

# 109 Side Mount Strap for CPVC Pipe



## CERTIFICATIONS



## FEATURES

Includes flared edges to protect piping

Rated for use with CPVC fire sprinkler pipe

Includes mounting screws

## SPECIFICATIONS

**Finish:** Pregalvanized

**Material:** Steel

Table 1/2


Catalog Number	Article Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A	B
1090075EG	597827	20	26.9 mm	5.8 mm	58.7 mm	42.9 mm
1090100EG	597828	25	33.7 mm	5.8 mm	66.7 mm	49.2 mm
1090125EG	597829	32	42.2 mm	5.8 mm	74.6 mm	58.7 mm

CatalogNumber	Article Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A	B
1090150EG	597831	40	48.3 mm	5.8 mm	81 mm	63.5 mm
1090200EG	597832	50	60.3 mm	5.8 mm	92.1 mm	76.2 mm

Table 2/2

Catalog Number	Article Number	C	Hanger Spacing
1090075EG	597827	30.2 mm	1.65 m Max
1090100EG	597828	30.2 mm	1.8 m Max
1090125EG	597829	30.2 mm	1.95 m Max
1090150EG	597831	30.2 mm	2.1 m Max
1090200EG	597832	30.2 mm	2.4 m Max

## DIAGRAMS

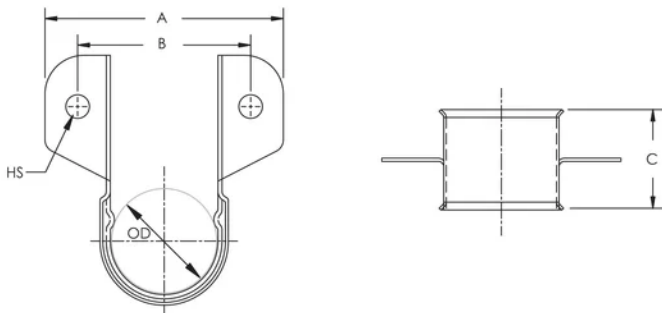

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

