

# Strut Beam Clip



## FEATURES

Beam Clip for clamping the open side of strut to a beam

Suitable for all strut channels

Requires installation in pairs

Structural attachment to beams to support nVent CADDY Eristrut

FM® Specification Tested

## SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	Flange Thickness (FT)	Hole Size (HS)	Length (L)
ZT605HD	313260	Steel	Hot-Dip Galvanized	16 mm Max	13 mm	49mm
ZTA605	388080	Steel	Hot-Dip Galvanized	16 mm Max	13 mm	49mm
ZTA605S6	387190	Stainless Steel 316 (EN 1.4401)		16 mm Max	13 mm	49mm

Table 2/2


Catalog Number	Article Number	Thickness (T)	Width (W)	Static Load	Screw Included
ZT605HD	313260	6 mm	40 mm	2040N	Yes

Catalog Number	Article Number	Thickness (T)	Width (W)	Static Load	Screw Included
ZTA605	388080	6 mm	40 mm	2040N	No
ZTA605S6	387190	6 mm	40 mm	2040N	No

### ADDITIONAL PRODUCT DETAILS

Indicated loads are based on installation with 1/2" (M12) hardware and strut channel type A.

### DIAGRAMS

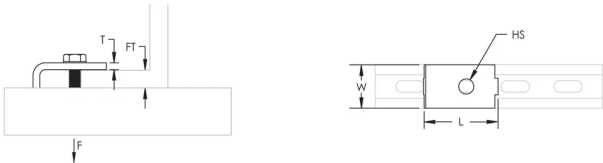

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

