


PEMSA Wire Basket Tray Cable Outlet

Data Solutions

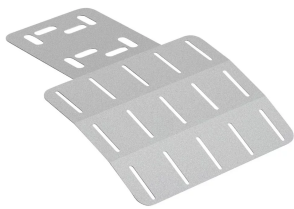

CERTIFICATIONS



FEATURES

Easy to install

Allows for easy exit angle adjustment (from 0 to 90 degrees)

SPECIFICATIONS


Material: Steel

Table 1/2

Catalog Number	Article Number	Color	Finish	Length (L)	Width 1 (W1)	Width 2 (W2)
WBTCBLOUT	820800		Pregalvanized	216mm	85mm	150mm
WBTCBLOUTBA	820801	Black		216mm	85mm	150mm

Table 2/2					
Catalog Number	Article Number	Thickness (T)	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Certifications
WBTCBLOUT	820800	1.5mm	7 – 20mm	3 – 30mm	CE, CADDY EU WBT CBL
WBTCBLOUTBA	820801	1.5mm	7 – 20mm	3 – 30mm	

DIAGRAMS

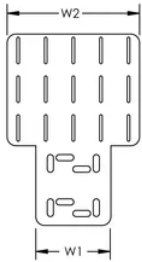

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE