


Cast Two Bolt Beam Bonding Clamp

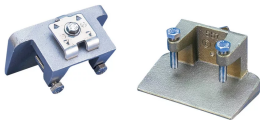

CERTIFICATIONS



FEATURES

Clamp for bonding cable to flat metal objects such as I-beams, angle irons and channel irons

Listed to UL® 96

SPECIFICATIONS

Conductor Size, UL: Class 1 - Class 2 (4/0 Max)

Table 1/2


Catalog Number	Material	Flange Thickness (FT)	Depth (D)	Height (H)	Width (W)	Contact Area
LPA557	Aluminum	25.4 mm Max	69.85mm	50.8 mm	101.6 mm	51.61 mm ² Min
LPC557	Copper	25.4 mm Max	69.85mm	50.8 mm	101.6 mm	51.61 mm ² Min

Table 2/2

Catalog Number	Unit Weight
----------------	-------------

LPA557	0.32 kg
LPC557	0.93 kg

DIAGRAMS

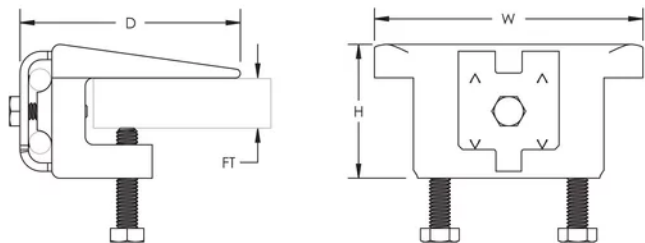

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE