


Joint Bond T6 Mold Welder Frame Assembly, Signal, W Bond Terminal Style, 50 mm² Ropelay

CATALOG NUMBER

SBXT6CE

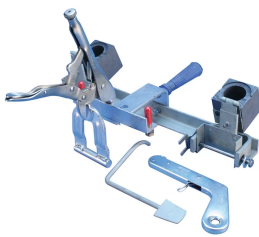

FEATURES

Replacement welder frame assembly for T6 joint bond welders

Includes frame with mold lid, mold handle, mold cleaner and flint ignitor

PRODUCT ATTRIBUTES

Article Number: 161120

Material: Graphite;Steel;Thermoplastic

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: W

Conductor Size: 50 mm² Ropelay

Conductor Outer Diameter, Nominal: 9.13mm

Welder Style: T6

Mold Only: No

Welding Material: SB25, Sold Separately

Bond Clip: B194G x 2, Sold Separately

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE