

# Glued Clip Kit



## FEATURES

Glued rail clips eliminate the need to drill any support where the clips need to be fixed, respecting the support integrity and improving safety

No tools needed; pre-applied hard-bonding glue makes installation easy and efficient

Resistant to corrosion-causing agents, including U.V., weather conditions, oil, greases, gasoline, solvents, rain and water

Helps increase lifetime of attached cable, reducing total project cost

Versatile base can accommodate different sizes of clips for different sizes of conductors and is usable for longitudinal or transversal cable applications

Each kit includes one container of adhesive suitable for a 10.1 oz. (300 ml) dispensing gun

Dispensing gun not included

## SPECIFICATIONS

**Temperature:** -40 to 93 °C

Table 1/2

Catalog Number	Article Number	Diameter (Ø)	Length (L)	Width (W)	Hole Size (HS)	Number of Base Plates Included
GCHSC1214	186035	12 - 14 mm	100mm	40 mm	7 mm	30
GCHSC1924	186055	19 - 24 mm	100mm	40 mm	7 mm	30
GCHSC2530	186065	25 - 30 mm	100mm	40 mm	7 mm	30


CatalogNumber	Article Number	Diameter (Ø)	Length (L)	Width (W)	Hole Size (HS)	Number ofBase PlatesIncluded
GCHSC78	187745	7 - 8 mm	100mm	40 mm	7 mm	30

Table 2/2			
Catalog Number	Article Number	Number of Clips Included	Clips Per Base Plate
GCHSC1214	186035	120	4 Max
GCHSC1924	186055	90	3 Max
GCHSC2530	186065	60	2 Max
GCHSC78	187745	120	4 Max

### ADDITIONAL PRODUCT DETAILS

3-clip configuration shown. 1- to 4-clip configurations also available.

### DIAGRAMS

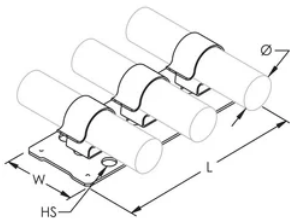

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**