


Busbar Adapter 32A With Cables, W060

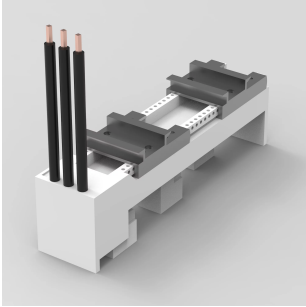

Busbar adapters adapted to the component manufacturers' design.

INDUSTRY STANDARDS

GL

FEATURES

Description: Busbar adapter, 32 A. With cables 6 mm². Adapted to the breaker manufacturer's design.

Rated voltage: 690 V

Rated current: 32 A

For busbars: 12, 15, 20, 25, 30 × 5, 10

Power dissipation at 80% load: 1,6 W

Width: 45 mm

Pack quantity: 1 pc.

Approvals: GL

SPECIFICATIONS

Table 1/1						
Catalog Number	Height	Width	Depth	Material	Finish	Color
32427	200mm	45mm	63mm	Plastic, Mild Steel	Plated	Black, Light Gray
32498	200mm	45mm	63mm	Plastic, Mild Steel	Plated	Black, Light Gray
32434	200mm	45mm	63mm	Plastic, Mild Steel	Plated	Black, Light Gray
32639	200mm	45mm	63mm	Plastic, Mild Steel	Plated	Black, Light Gray

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE