

# PPP Parallel Plastic Screw-In Plug for P13/P14, European Design



The European Design Version (Suffix EE) is currently being phased out. All future projects should be designed with the Worldwide Design Version (Suffixes N and LN). This change is being done in order to simplify our product offering and eliminate redundant designs. Please contact Customer Care or your local Sales Engineer/Manager if you require more information on this transition.

## FEATURES

Designed for use with the P13/P14 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Color coded for the appropriate coupler size

## SPECIFICATIONS

**Design Version:** European (Specialty Materials)


Table 1/2

Catalog Number	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL1012PPP	153240	10 mm, 12 mm	#3, #4	10M	22 mm	13 mm
EL1416PPP	153280	14 mm, 16 mm	#5	15M	27 mm	13 mm
EL18PPP	153310	18 mm			33 mm	16 mm
EL20PPP	153320	20 mm	#6	20M	33 mm	16 mm
EL2225PPP	153360	22 mm, 25 mm	#7, #8	25M	41 mm	16 mm

CatalogNumber	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL2830PPP	153380	28 mm, 30 mm	#9	30M	46 mm	16 mm
EL32PPP	153400	32 mm	#10		52 mm	16 mm
EL40PPP	153420	40 mm			64 mm	16 mm

Table 2/2		
Catalog Number	Article Number	Color
EL1012PPP	153240	Red
EL1416PPP	153280	Black
EL18PPP	153310	White
EL20PPP	153320	Yellow
EL2225PPP	153360	Red
EL2830PPP	153380	Black
EL32PPP	153400	Yellow
EL40PPP	153420	Green

### DIAGRAMS

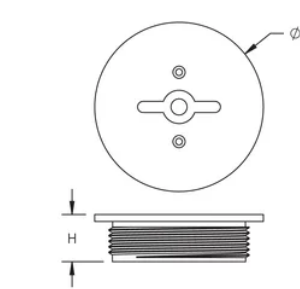

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**