

Metal Pressure Clip

FEATURES GUIDE

SAFETY FEATURES

100% steel for more durability


nVent CADDY Armour coating for maximum corrosion protection

Smooth rounded edges to protect the cables from damage

PKMININSERT can be added to the Metal Pressure Clip to make it an E30 fire-rated solution per DIN 4102-12, ideal for use at points of egress

EASE OF USE FEATURES

Cutouts make insertion of cables easier while maintaining strength and sturdiness

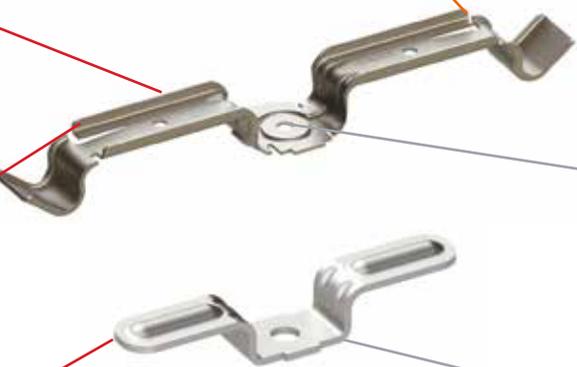

FLEXIBILITY FEATURES

Available in several different configurations to fit the end-users' needs

Two different lengths to support up to 16 10 mm cables

Two different center hole sizes are compatible with either battery- and gas-actuated nail guns or M6 hardware

Insert can be purchased separately or in kits with the Metal Pressure Clips

Low-profile design makes the solution ideal for projects with tight spaces such as high rise buildings

Can be used on ceiling and wall applications

The color of the line corresponds to the larger goal of each feature:

- SAFETY FEATURES
- EASE OF USE FEATURES
- FLEXIBILITY FEATURES