


# Air Baffle for AMC Filler Module ECO

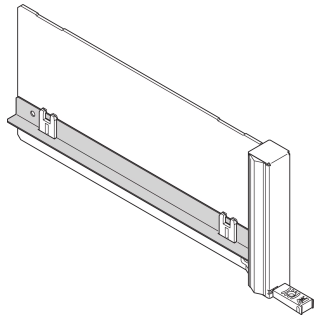

Air baffles block airflow in the slot they are installed into, directing air flow to active modules in the system.

## CERTIFICATIONS



## FEATURES

Retrofittable; simply clip onto the PCB of the filler module

To adjust the airflow volume the plastic cover can be individually cut to size (not for compact modules)

## SPECIFICATIONS

<b>Type:</b>	AdvancedMC Filler Module
<b>Product Type:</b>	Air Baffle
<b>Product Family:</b>	MicroTCA
<b>Material:</b>	Stainless Steel
<b>Works With:</b>	Systems

Table 1/1

Catalog Number	Design Feature	Package Quantity	Quick Ship
20849-356	Mid-Size	10	No
20849-357	Full-Size	10	No

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**