


# Air Baffle, U-Front Panel, Refrofit Shielding, Textile

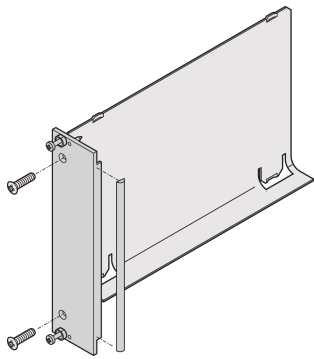

The air baffle with U-shaped front panel covers an empty slot to eliminate an air flow exit. The U-shaped front panel accepts a textile EMC gasket.

## CERTIFICATIONS



## FEATURES

air baffle eliminates air leaks in empty slots

Cover is pushed into the guide rail

## SPECIFICATIONS

<b>Product Type:</b>	Air Baffle
<b>Material:</b>	Aluminum
<b>Finish:</b>	Anodized; Passivated
<b>Product Family:</b>	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac
<b>Type:</b>	With Front Panel

Table 1/2

Catalog Number	Rack Height	Package Quantity	Depth	EMC Shielding	Rack Width	Works With
20848-728	3U	1	160mm	No (Retrofittable)	4HP	Subracks, Cases

CatalogNumber	Rack Height	Package Quantity	Depth	EMC Shielding	Rack Width	Works With
20848-729	3U	1	220mm	No (Retrofittable)	4HP	Sub racks, Cases
20848-736	6U	1	160mm	No (Retrofittable)	4HP	Sub racks, Cases
20848-737	6U	1	220mm	No (Retrofittable)	4HP	Sub racks, Cases

Table 2/2

Catalog Number	Quick Ship
20848-728	No
20848-729	No
20848-736	No
20848-737	No

## ADDITIONAL PRODUCT DETAILS

Air baffle for 280 mm deep and for 80 mm rear I/O boards available on request.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**