


# Front Handle, for Type R Side Panels

## CATALOG NUMBER

**24566-010**

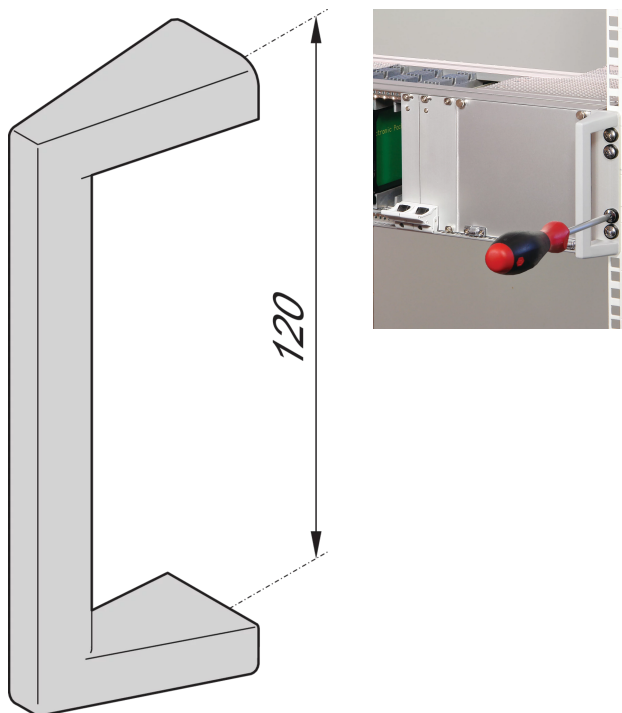

The front handle for a rugged subrack have a load-carrying capacity 30 kg. It optimizes the assembly of a subrack into a cabinet.

## CERTIFICATIONS



## FEATURES

Load-carrying capacity 30 kg

Suitable for 3 and 6 U side panels

The form of the handle make it much easier to assemble the M6 fixing screws

PRODUCT ATTRIBUTES

Product Type: Handle
Works With: Subracks
Handle Type: Straight
Width: 12.2mm
Material: Aluminum
Color: Silver
Package Quantity: 2
Depth: 40mm
Finish: Powder Coated
Torque: 2.4N·m

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE