
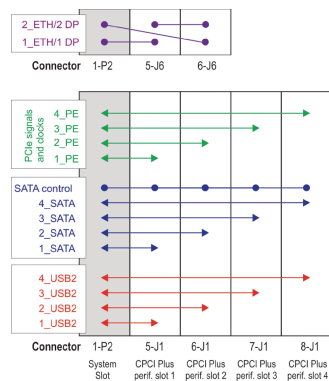
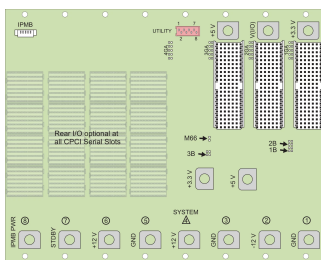
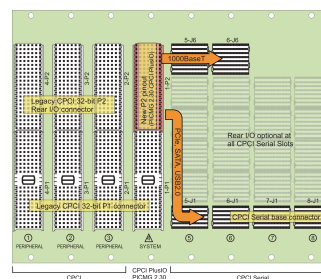
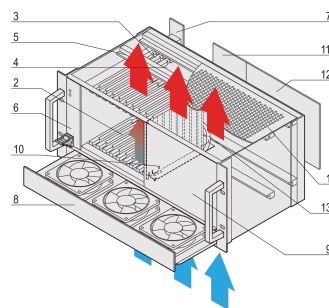


CPCI PlusIO System With Pluggable PSU, 4 U, 8 Slot

CATALOG NUMBER

24579-400

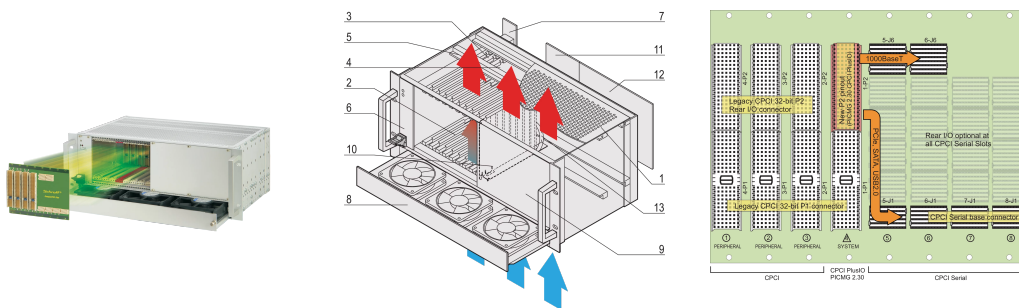

4 U CompactPCI PlusIO System with vertical Card Cage for one CPCI PlusIO System Controller, 4 CompactPCI and 3 CompactPCI Serial Peripheral Boards and one CompactPCI 3 U Pluggable Power Supply.

CERTIFICATIONS



FEATURES

In accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; backplane in accordance with PICMG 2.0 rev. 3.0 and PICMG 2.30 rev. 1.0

System with vertical card cage. Board format Front: 3 U, 160 mm deep, 8 slot; Rear I/O: 3 U, 80 mm deep, 3 slot

Backplane 4 slot, 3 U, 32 bit, CompactPCI; 4 slot, 3 U, CompactPCI PlusIO

Heat dissipation by 1 U hot-swap fan unit, airflow bottom to top

19"-compatible PSU, 250 W, 3 U, 8 HP

Option to mount a hard disk

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 8

Type: 19" Rack Mount

Backplane Type: 3 U, 4 Slot CompactPCI and 4 Slot CompactPCI Serial

Data Transfer: 32-bit PCI Bus; PCIe Gen2

Power per Slot: 40W

Input Voltage AC: 100 – 240V

Airflow Direction: Bottom to Top

Rack Height: 4U

Power Supply Type: (1) Pluggable PSU

Power Supply Included: Yes

Rear I/O: Yes

Complies With: PICMG 2.30 R1.0

Depth: 275mm

Height: 177mm

Net Weight: 10.8kg

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Modified systems available on request.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE