



# Front Panel 1 U, Horizontal Rail Mounting

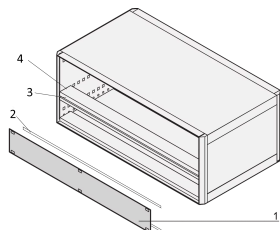

The 1 U front panel enables a user to cover the 1 U section in a 4 U PropacPRO case, RatiopacPRO 5 U (1-3-1) and EuropacPRO 4 U. The panel will be assembled to the threaded inserts of the horizontal rails.

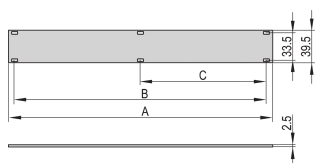

## CERTIFICATIONS



## FEATURES

Mounts on horizontal rails (upper, lower)

## SPECIFICATIONS

<b>Material:</b>	Aluminum
<b>Finish:</b>	Anodized; Passivated
<b>Product Family:</b>	RatiopacPRO; PropacPRO; EuropacPRO
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel


Table 1/2

Catalog Number	Rack Height	Height (H)	Rack Width	Width (W)	Depth (D)	Package Quantity
20850-424	1U	39.5mm	42HP	213mm	2.5mm	1

CatalogNumber	Rack Height	Height (H)	Rack Width	Width (W)	Depth (D)	Package Quantity
20850-425	1U	39.5mm	63HP	319.7mm	2.5mm	1
20850-426	1U	39.5mm	84HP	426.4mm	2.5mm	1
20850-423	1U	39.5mm	28HP	141.9mm	2.5mm	1

Table 2/2				
Catalog Number	Front Finish	Rear Finish	Treated Edges	Quick Ship
20850-424	Anodized	Conductive	No	No
20850-425	Anodized	Conductive	No	No
20850-426	Anodized	Conductive	No	No
20850-423	Anodized	Conductive	No	No

## DIAGRAMS

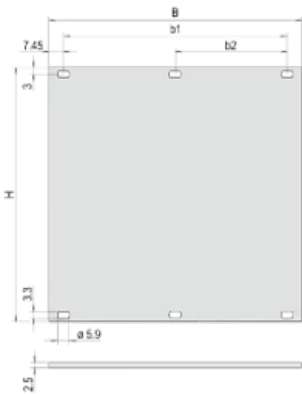

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**