

# nVent CADDY Speed Link SLK with Nail Gun Bracket



## FEATURES

Complete system includes wire, locking device and concrete nail gun insert bracket

Clips onto nozzle of gas or battery-actuated nail guns allowing for hands-off installation at structure or from the floor using a pole

Longer leg angle bracket for tool clearance

Quickly and easily attaches to concrete, steel or composite metal decking

## SPECIFICATIONS

|                                   |                                      |
|-----------------------------------|--------------------------------------|
| <b>Wire Rope Diameter:</b>        | 1.5 mm                               |
| <b>Static Load Safety Factor:</b> | 5:1                                  |
| <b>Finish:</b>                    | Electrogalvanized                    |
| <b>Material:</b>                  | Steel;Zinc Alloy;Polypropylene;Nylon |
| <b>Complies With:</b>             | SMACNA HVAC-DCS                      |

Table 1/1

| Catalog Number | Article Number | Wire Rope Length | A     | B       | Static Load |
|----------------|----------------|------------------|-------|---------|-------------|
| SLK15L2GBSF    | 197812         | 2m               | 38 mm | 25.5 mm | 195N        |
| SLK15L3GBSF    | 197813         | 3m               | 38 mm | 25.5 mm | 195N        |

**Thickness (T):** 12.5 mm


**Width (W):** 19 mm  
**Height (H):** 55 mm  
**Angle (a):** 90 ° Max

### ADDITIONAL PRODUCT DETAILS

Static Load represents the static load of the nail gun insert assembly. Please consult with the nail manufacturer to evaluate the static load of the nail and type of concrete used for the installation. Maximum load is the lesser of the static load from the nail manufacturer or the published load for the assembly.

Nail gun insert is compatible with BeA® CN60-688ES, Hilti® BX 3, GX 3, DEWALT® Trak-It C3, SPIT® PULSA 40E, 800E, 700, 1000 or equivalent nailers.

### DIAGRAMS

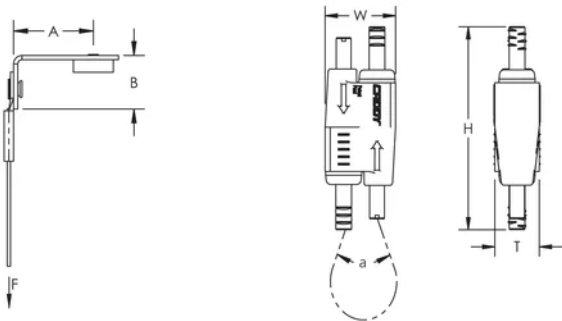

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

