


## Varistar CP Mobile Base/Plinth

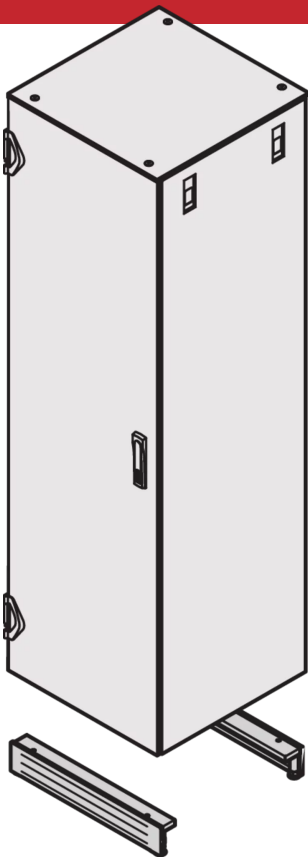

Mobile base/plinth to make a cabinet mobile.

### FEATURES

---

Covers, St, 1.5 mm

Load-carrying capacity on casters 400 kg, on adjustable feet 1600 kg

Support, St, 3 mm

Color RAL 7021

Plinth height H = 103 mm, with feet adjustable from 126 to 134 mm

### SPECIFICATIONS

---

**Product Type:** Cabinet/Rack Base

**Material:** Steel

Table 1/2

Catalog Number	Width	Depth	Package Quantity	Color	Color Code	Finish
21630-658	600mm	1000mm	1	Black Grey	RAL 7021	Powder Coated
21630-655	600mm	600mm	1	Black Grey	RAL 7021	Powder Coated
21630-663	800mm	900mm	1	Black Grey	RAL 7021	Powder Coated
21630-661	800mm	600mm	1			Powder Coated
21630-664	800mm	1000mm	1	Black Grey	RAL 7021	Powder Coated
21630-657	600mm	900mm	1	Black Grey	RAL 7021	Powder Coated
21630-662	800mm	800mm	1	Black Grey	RAL 7021	Powder Coated
21630-656	600mm	800mm	1	Black Grey	RAL 7021	Powder Coated

Table 2/2

Catalog Number	Type	Works With	Quick Ship
21630-658	Base Plinth, Mobile	Varistar CP	No
21630-655	Base Plinth, Mobile	Varistar CP	No
21630-663	Base Plinth, Mobile	Varistar CP	No
21630-661	Base Plinth, Mobile	Varistar CP	No
21630-664	Base Plinth, Mobile	Varistar CP	No
21630-657	Base Plinth, Mobile	Varistar CP	No
21630-662	Base Plinth, Mobile	Varistar CP	No
21630-656	Base Plinth, Mobile	Varistar CP	No

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**