

# APY External Horizontal Wall Bracket



## FEATURES

Side mount saddle support for C-Profiles and strut

Complete with fixings

## SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Finish	Channel Type	Strut Type	Height (H)
APYSTRUTS6	584840	Stainless Steel 316 (EN 1.4401)			A (41 x 41 mm), C (21 x 41 mm)	50 mm
APYE23EG	584740	Steel	Electrogalvanized	E2L, E2, E3		40 mm
APYE4STRUTEG	584751	Steel	Electrogalvanized	E4	A (41 x 41 mm), C (21 x 41 mm)	50 mm
APYE01EG	584758	Steel	Electrogalvanized	E0L, E0, E1		40 mm

Table 2/2

Catalog Number	Article Number	Width (W)	Thickness (T)	A	B	C
APYSTRUTS6	584840	144 mm	5 mm	43 mm	12 mm	19 mm

CatalogNumber	Article Number	Width (W)	Thickness (T)	A	B	C
APYE23EG	584740	124 mm	5 mm	36 mm	12 mm	19 mm
APYE4STRUTE G	584751	144 mm	5 mm	43 mm	12 mm	19 mm
APYE01EG	584758	124 mm	5 mm	31 mm	12 mm	19 mm

### DIAGRAMS

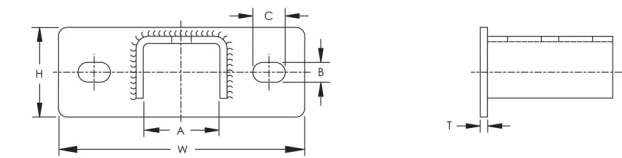

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

#### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

#### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

#### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

