


Cantilever Arm with EOL Channel

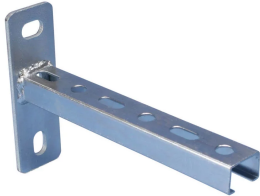

CERTIFICATIONS



FEATURES

Perforated, cold rolled

Slotted backplate

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/1

Catalog Number	Article Number	Length (L)
CE0L13H0300EG	599880	300mm
CE0L13H0180EG	599879	180mm


Thickness (T): 1.25 mm

E: 4 mm

Y: 8.5 x 20 mm

Hole Size (HS): 10.5 mm
X: 11 x 18 mm
C: 15.5 mm
A: 18 mm
B: 27 mm
Width (W): 40 mm
D: 60 mm
Height (H): 120 mm

DIAGRAMS

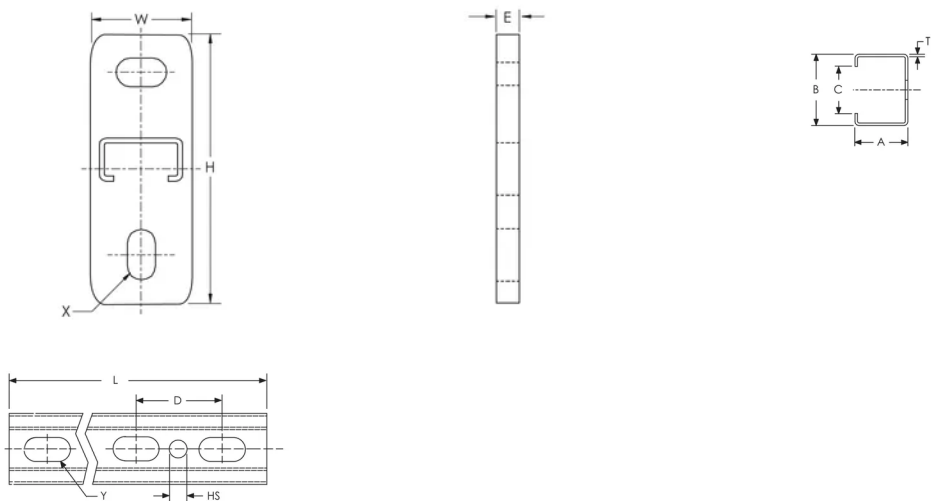

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY **ERICO** **HOFFMAN** **ILSCO** **SCHROFF** **TRACHTE**

