

# Heavy Duty Pipe Clamp



## FEATURES

For high static requirements in industrial construction

Suitable for fix point applications

## SPECIFICATIONS

**Finish:** Painted;Red Oxide

**Material:** Steel

Table 1/2

| Catalog Number | Article Number | Outer Diameter (OD) | NB/DN | Hole Size (HS) | Screw Diameter (Sc) | Screw Length (L) |
|----------------|----------------|---------------------|-------|----------------|---------------------|------------------|
| SSG022RO       | 574600         | 20.5 - 22 mm        | 15    | 6.6 mm         | 6 mm                | 20mm             |
| SSG028RO       | 574610         | 26.5 - 28 mm        | 20    | 6.6 mm         | 6 mm                | 20mm             |
| SSG035RO       | 574620         | 33 - 35 mm          | 25    | 11 mm          | 10 mm               | 40mm             |
| SSG043RO       | 574630         | 40 - 43 mm          | 32    | 11 mm          | 10 mm               | 40mm             |
| SSG049RO       | 574640         | 48 - 49 mm          | 40    | 11 mm          | 10 mm               | 40mm             |
| SSG061RO       | 574650         | 57.0 - 60.3 mm      | 50    | 11 mm          | 10 mm               | 40mm             |

| CatalogNumber | Article Number | Outer Diameter (OD) | NB/DN | Hole Size (HS) | ScrewDiameter (Sc) | Screw Length (L) |
|---------------|----------------|---------------------|-------|----------------|--------------------|------------------|
| SSG077RO      | 574660         | 75 - 77 mm          | 65    | 11 mm          | 10 mm              | 40mm             |
| SSG090RO      | 574670         | 88 - 90 mm          | 80    | 11 mm          | 10 mm              | 40mm             |
| SSG115RO      | 574680         | 110 - 115 mm        | 100   | 18 mm          | 16 mm              | 60mm             |
| SSG141RO      | 574685         | 139 - 141 mm        | 125   | 18 mm          | 16 mm              | 60mm             |
| SSG170RO      | 574690         | 165 - 170 mm        | 150   | 18 mm          | 16 mm              | 60mm             |
| SSG0359RO     | 574725         | 355 - 363 mm        |       | 22 mm          | 20 mm              | 80mm             |
| SSG222RO      | 574700         | 216 - 222 mm        | 200   | 22 mm          | 20 mm              | 80mm             |
| SSG276RO      | 574710         | 267 - 276 mm        | 250   | 22 mm          | 20 mm              | 80mm             |
| SSG327RO      | 574720         | 321 - 327 mm        | 300   | 22 mm          | 20 mm              | 80mm             |
| SSG410RO      | 574730         | 403 - 410 mm        | 400   | 26 mm          | 24 mm              | 80mm             |

Table 2/2


| Catalog Number | Article Number | Static Load | Width (W) | Thickness (T) | A      |
|----------------|----------------|-------------|-----------|---------------|--------|
| SSG022RO       | 574600         | 1000N       | 23 mm     | 3 mm          | 46 mm  |
| SSG028RO       | 574610         | 1000N       | 23 mm     | 3 mm          | 52 mm  |
| SSG035RO       | 574620         | 1000N       | 40 mm     | 4 mm          | 71 mm  |
| SSG043RO       | 574630         | 1000N       | 40 mm     | 4 mm          | 79 mm  |
| SSG049RO       | 574640         | 1000N       | 40 mm     | 4 mm          | 85 mm  |
| SSG061RO       | 574650         | 1800N       | 40 mm     | 4 mm          | 97 mm  |
| SSG077RO       | 574660         | 1400N       | 40 mm     | 4 mm          | 113 mm |

| Catalog Number | Article Number | Static Load | Width (W) | Thickness (T) | A      |
|----------------|----------------|-------------|-----------|---------------|--------|
| SSG090R0       | 574670         | 1200N       | 40 mm     | 4 mm          | 126 mm |
| SSG115R0       | 574680         | 2900N       | 50 mm     | 6 mm          | 167 mm |
| SSG141R0       | 574685         | 2500N       | 50 mm     | 6 mm          | 193 mm |
| SSG170R0       | 574690         | 2200N       | 50 mm     | 6 mm          | 222 mm |
| SSG0359R0      | 574725         | 2600N       | 60 mm     | 8 mm          | 427 mm |
| SSG222R0       | 574700         | 3600N       | 60 mm     | 8 mm          | 290 mm |
| SSG276R0       | 574710         | 3100N       | 60 mm     | 8 mm          | 344 mm |
| SSG327R0       | 574720         | 2800N       | 60 mm     | 8 mm          | 395 mm |
| SSG410R0       | 574730         | 4100N       | 70 mm     | 10 mm         | 492 mm |

## ADDITIONAL PRODUCT DETAILS

Static load refers to a complete set of Heavy Duty Pipe Clamps held in place with indicated screws per ISO 4014 and corresponding hex nuts per ISO 4032 (for further information, please refer to Standard SSG 7075E).

## DIAGRAMS

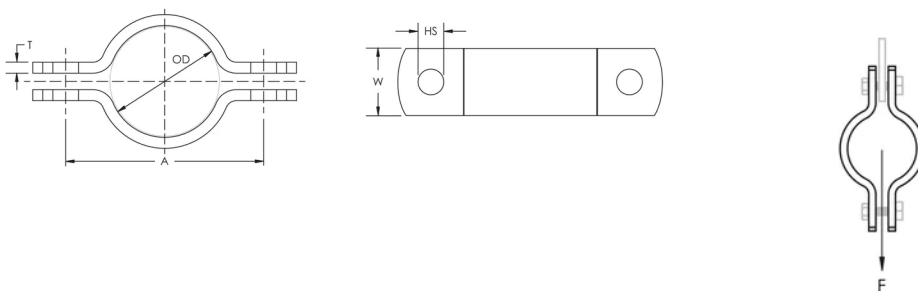

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

