

Strut T-Bolt



FEATURES

Pre-mounted with large washer and nut


SPECIFICATIONS

Table 1/1

Catalog Number	Article Number	Material	Finish	Rod Size (RS)	Length (L)	A
TMN08060EG	590222	Steel	Electrogalvanized	8	60mm	6 mm
TMN08030EG	590220	Steel	Electrogalvanized	8	30mm	6 mm
TMN08050EG	590221	Steel	Electrogalvanized	8	50mm	6 mm
TMN08100EG	590223	Steel	Electrogalvanized	8	100mm	6 mm
TMN08040EG	590080	Steel	Electrogalvanized	8	40mm	6 mm
TMN08040S4	590093	Stainless Steel 304 (EN 1.4301)		8	40mm	6 mm
TMN10030EG	590218	Steel	Electrogalvanized	10	30mm	8 mm

CatalogNumber	Article Number	Material	Finish	Rod Size (RS)	Length (L)	A
TMN10060EG	590225	Steel	Electrogalvaniz ed	10	60mm	8 mm
TMN12040EG	590100	Steel	Electrogalvaniz ed	12	40mm	8 mm
TMN10040EG	590090	Steel	Electrogalvaniz ed	10	40mm	8 mm
TMN10040S4	590094	Stainless Steel 304 (EN 1.4301)		10	40mm	8 mm
TMN10050EG	590224	Steel	Electrogalvaniz ed	10	50mm	8 mm

DIAGRAMS

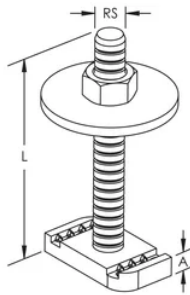

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

