


# Novastar Side Panel for Slim-Line

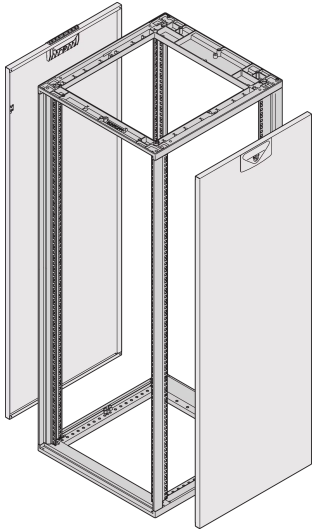

Steel Side Panels for Slim.Line aluminum frame with quick fastner for easy mounting and installation. Schroff delivers cladding parts with grounding cable installed and tested

## CERTIFICATIONS



## FEATURES

Side panel with quarter-turn fastener, includes grounding

St, 1 mm

## SPECIFICATIONS

**Product Type:** Cabinet/Rack Panel

**Material:** Steel

Table 1/2

Catalog Number	Rack Height	Height	Depth	Package Quantity	Color	Color Code
26230-173	16U	709mm	800mm	2	Light Grey	RAL 7035

<b>CatalogNumber</b>	<b>Rack Height</b>	<b>Height</b>	<b>Depth</b>	<b>Package Quantity</b>	<b>Color</b>	<b>Color Code</b>
26230-136	43U	1909mm	1000mm	2	Light Grey	RAL 7035
26230-137	47U	2087mm	900mm	2	Light Grey	RAL 7035
26230-138	47U	2087mm	1000mm	2	Light Grey	RAL 7035
26230-172	12U	589mm	800mm	2	Light Grey	RAL 7035
26230-174	20U	945mm	800mm	2	Light Grey	RAL 7035
26230-175	25U	1167mm	800mm	2	Light Grey	RAL 7035
26230-176	34U	1567mm	800mm	2	Light Grey	RAL 7035
26230-177	38U	1745mm	800mm	2	Light Grey	RAL 7035
26230-178	43U	1967mm	800mm	2	Light Grey	RAL 7035
26230-179	47U	2145mm	800mm	2	Light Grey	RAL 7035
25230-160	29U	1345mm	500mm	2	Black Grey	RAL 7021
25230-161	29U	1345mm	600mm	2	Black Grey	RAL 7021
25230-162	29U	1345mm	800mm	2	Black Grey	RAL 7021
25230-163	29U	1345mm	900mm	2	Black Grey	RAL 7021
25230-164	29U	1345mm	1000mm	2	Black Grey	RAL 7021
26230-160	29U	1345mm	500mm	2	Light Grey	RAL 7035
26230-161	29U	1345mm	600mm	2	Light Grey	RAL 7035
26230-162	29U	1345mm	800mm	2	Light Grey	RAL 7035

<b>CatalogNumber</b>	<b>Rack Height</b>	<b>Height</b>	<b>Depth</b>	<b>Package Quantity</b>	<b>Color</b>	<b>Color Code</b>
26230-163	29U	1345mm	900mm	2	Light Grey	RAL 7035
26230-164	29U	1345mm	1000mm	2	Light Grey	RAL 7035
25230-070	6U	357mm	500mm	2	Black Grey	RAL 7021
25230-071	9U	490mm	500mm	2	Black Grey	RAL 7021
25230-072	12U	589mm	500mm	2	Black Grey	RAL 7021
25230-073	16U	709mm	500mm	2	Black Grey	RAL 7021
25230-074	20U	945mm	500mm	2	Black Grey	RAL 7021
25230-075	25U	1167mm	500mm	2	Black Grey	RAL 7021
25230-076	34U	1567mm	500mm	2	Black Grey	RAL 7021
25230-077	38U	1745mm	500mm	2	Black Grey	RAL 7021
25230-078	43U	1967mm	500mm	2	Black Grey	RAL 7021
25230-079	47U	2145mm	500mm	2	Black Grey	RAL 7021
25230-113	12U	531mm	900mm	2	Black Grey	RAL 7021
25230-114	12U	531mm	1000mm	2	Black Grey	RAL 7021
25230-115	16U	709mm	900mm	2	Black Grey	RAL 7021
25230-116	16U	709mm	1000mm	2	Black Grey	RAL 7021
25230-117	20U	887mm	900mm	2	Black Grey	RAL 7021
25230-118	20U	887mm	1000mm	2	Black Grey	RAL 7021

<b>CatalogNumber</b>	<b>Rack Height</b>	<b>Height</b>	<b>Depth</b>	<b>Package Quantity</b>	<b>Color</b>	<b>Color Code</b>
25230-119	25U	1109mm	900mm	2	Black Grey	RAL 7021
25230-120	6U	357mm	600mm	2	Black Grey	RAL 7021
25230-121	9U	490mm	600mm	2	Black Grey	RAL 7021
25230-122	12U	589mm	600mm	2	Black Grey	RAL 7021
25230-123	16U	709mm	600mm	2	Black Grey	RAL 7021
25230-124	20U	945mm	600mm	2	Black Grey	RAL 7021
25230-125	25U	1167mm	600mm	2	Black Grey	RAL 7021
25230-126	34U	1567mm	600mm	2	Black Grey	RAL 7021
25230-127	38U	1745mm	600mm	2	Black Grey	RAL 7021
25230-128	43U	1967mm	600mm	2	Black Grey	RAL 7021
25230-129	47U	2145mm	600mm	2	Black Grey	RAL 7021
25230-130	25U	1109mm	1000mm	2	Black Grey	RAL 7021
25230-131	34U	1509mm	900mm	2	Black Grey	RAL 7021
25230-132	34U	1509mm	1000mm	2	Black Grey	RAL 7021
25230-133	38U	1687mm	900mm	2	Black Grey	RAL 7021
25230-134	38U	1687mm	1000mm	2	Black Grey	RAL 7021
25230-135	43U	1909mm	900mm	2	Black Grey	RAL 7021
25230-136	43U	1909mm	1000mm	2	Black Grey	RAL 7021

<b>CatalogNumber</b>	<b>Rack Height</b>	<b>Height</b>	<b>Depth</b>	<b>Package Quantity</b>	<b>Color</b>	<b>Color Code</b>
25230-137	47U	2087mm	900mm	2	Black Grey	RAL 7021
25230-138	47U	2087mm	1000mm	2	Black Grey	RAL 7021
25230-172	12U	589mm	800mm	2	Black Grey	RAL 7021
25230-173	16U	709mm	800mm	2	Black Grey	RAL 7021
25230-174	20U	945mm	800mm	2	Black Grey	RAL 7021
25230-175	25U	1167mm	800mm	2	Black Grey	RAL 7021
25230-176	34U	1567mm	800mm	2	Black Grey	RAL 7021
25230-177	38U	1745mm	800mm	2	Black Grey	RAL 7021
25230-178	43U	1967mm	800mm	2	Black Grey	RAL 7021
25230-179	47U	2145mm	800mm	2	Black Grey	RAL 7021
26230-070	6U	357mm	500mm	2	Light Grey	RAL 7035
26230-071	9U	490mm	500mm	2	Light Grey	RAL 7035
26230-072	12U	589mm	500mm	2	Light Grey	RAL 7035
26230-073	16U	709mm	500mm	2	Light Grey	RAL 7035
26230-074	20U	945mm	500mm	2	Light Grey	RAL 7035
26230-075	25U	1167mm	500mm	2	Light Grey	RAL 7035
26230-076	34U	1567mm	500mm	2	Light Grey	RAL 7035
26230-077	38U	1745mm	500mm	2	Light Grey	RAL 7035

<b>CatalogNumber</b>	<b>Rack Height</b>	<b>Height</b>	<b>Depth</b>	<b>Package Quantity</b>	<b>Color</b>	<b>Color Code</b>
26230-078	43U	1967mm	500mm	2	Light Grey	RAL 7035
26230-079	47U	2145mm	500mm	2	Light Grey	RAL 7035
26230-113	12U	531mm	900mm	2	Light Grey	RAL 7035
26230-114	12U	531mm	1000mm	2	Light Grey	RAL 7035
26230-115	16U	709mm	900mm	2	Light Grey	RAL 7035
26230-116	16U	709mm	1000mm	2	Light Grey	RAL 7035
26230-117	20U	887mm	900mm	2	Light Grey	RAL 7035
26230-118	20U	887mm	1000mm	2	Light Grey	RAL 7035
26230-119	25U	1109mm	900mm	2	Light Grey	RAL 7035
26230-120	6U	357mm	600mm	2	Light Grey	RAL 7035
26230-121	9U	490mm	600mm	2	Light Grey	RAL 7035
26230-122	12U	589mm	600mm	2	Light Grey	RAL 7035
26230-123	16U	709mm	600mm	2	Light Grey	RAL 7035
26230-124	20U	945mm	600mm	2	Light Grey	RAL 7035
26230-125	25U	1167mm	600mm	2	Light Grey	RAL 7035
26230-126	34U	1567mm	600mm	2	Light Grey	RAL 7035
26230-127	38U	1745mm	600mm	2	Light Grey	RAL 7035
26230-128	43U	1967mm	600mm	2	Light Grey	RAL 7035

CatalogNumber	Rack Height	Height	Depth	Package Quantity	Color	Color Code
26230-129	47U	2145mm	600mm	2	Light Grey	RAL 7035
26230-130	25U	1109mm	1000mm	2	Light Grey	RAL 7035
26230-131	34U	1509mm	900mm	2	Light Grey	RAL 7035
26230-132	34U	1509mm	1000mm	2	Light Grey	RAL 7035
26230-133	38U	1687mm	900mm	2	Light Grey	RAL 7035
26230-134	38U	1687mm	1000mm	2	Light Grey	RAL 7035
26230-135	43U	1909mm	900mm	2	Light Grey	RAL 7035

Table 2/2

Catalog Number	Finish	Type	Certifications	Quick Ship
26230-173	Powder Coated	Side Panel	RoHS	No
26230-136	Powder Coated	Side Panel	RoHS	No
26230-137	Powder Coated	Side Panel	RoHS	No
26230-138	Powder Coated	Side Panel	RoHS	No
26230-172	Powder Coated	Side Panel	RoHS	No
26230-174	Powder Coated	Side Panel	RoHS	No
26230-175	Powder Coated	Side Panel	RoHS	No
26230-176	Powder Coated	Side Panel	RoHS	No
26230-177	Powder Coated	Side Panel	RoHS	No
26230-178	Powder Coated	Side Panel	RoHS	No

Catalog Number	Finish	Type	Certifications	Quick Ship
26230-179	Powder Coated	Side Panel	RoHS	No
25230-160	Powder Coated	Side Panel		No
25230-161	Powder Coated	Side Panel		No
25230-162	Powder Coated	Side Panel		No
25230-163	Powder Coated	Side Panel		No
25230-164	Powder Coated	Side Panel		No
26230-160	Powder Coated	Side Panel		No
26230-161	Powder Coated	Side Panel		No
26230-162	Powder Coated	Side Panel		No
26230-163	Powder Coated	Side Panel		No
26230-164	Powder Coated	Side Panel		No
25230-070	Powder Coated	Side Panel	RoHS	No
25230-071	Powder Coated	Side Panel	RoHS	No
25230-072	Powder Coated	Side Panel	RoHS	No
25230-073	Powder Coated	Side Panel	RoHS	No
25230-074	Powder Coated	Side Panel	RoHS	No
25230-075	Powder Coated	Side Panel	RoHS	No
25230-076	Powder Coated	Side Panel	RoHS	No



Catalog Number	Finish	Type	Certifications	Quick Ship
25230-077	Powder Coated	Side Panel	RoHS	No
25230-078	Powder Coated	Side Panel	RoHS	No
25230-079	Powder Coated	Side Panel	RoHS	No
25230-113	Powder Coated	Side Panel	RoHS	No
25230-114	Powder Coated	Side Panel	RoHS	No
25230-115	Powder Coated	Side Panel	RoHS	No
25230-116	Powder Coated	Side Panel	RoHS	No
25230-117	Powder Coated	Side Panel	RoHS	No
25230-118	Powder Coated	Side Panel	RoHS	No
25230-119	Powder Coated	Side Panel	RoHS	No
25230-120	Powder Coated	Side Panel	RoHS	No
25230-121	Powder Coated	Side Panel	RoHS	No
25230-122	Powder Coated	Side Panel	RoHS	No
25230-123	Powder Coated	Side Panel	RoHS	No
25230-124	Powder Coated	Side Panel	RoHS	No
25230-125	Powder Coated	Side Panel	RoHS	No
25230-126	Powder Coated	Side Panel	RoHS	No
25230-127	Powder Coated	Side Panel	RoHS	No

Catalog Number	Finish	Type	Certifications	Quick Ship
25230-128	Powder Coated	Side Panel	RoHS	No
25230-129	Powder Coated	Side Panel	RoHS	No
25230-130	Powder Coated	Side Panel	RoHS	No
25230-131	Powder Coated	Side Panel	RoHS	No
25230-132	Powder Coated	Side Panel	RoHS	No
25230-133	Powder Coated	Side Panel	RoHS	No
25230-134	Powder Coated	Side Panel	RoHS	No
25230-135	Powder Coated	Side Panel	RoHS	No
25230-136	Powder Coated	Side Panel	RoHS	No
25230-137	Powder Coated	Side Panel	RoHS	No
25230-138	Powder Coated	Side Panel	RoHS	No
25230-172	Powder Coated	Side Panel	RoHS	No
25230-173	Powder Coated	Side Panel	RoHS	No
25230-174	Powder Coated	Side Panel	RoHS	No
25230-175	Powder Coated	Side Panel	RoHS	No
25230-176	Powder Coated	Side Panel	RoHS	No
25230-177	Powder Coated	Side Panel	RoHS	No
25230-178	Powder Coated	Side Panel	RoHS	No

Catalog Number	Finish	Type	Certifications	Quick Ship
25230-179	Powder Coated	Side Panel	RoHS	No
26230-070	Powder Coated	Side Panel	RoHS	No
26230-071	Powder Coated	Side Panel	RoHS	No
26230-072	Powder Coated	Side Panel	RoHS	No
26230-073	Powder Coated	Side Panel	RoHS	No
26230-074	Powder Coated	Side Panel	RoHS	No
26230-075	Powder Coated	Side Panel	RoHS	No
26230-076	Powder Coated	Side Panel	RoHS	No
26230-077	Powder Coated	Side Panel	RoHS	No
26230-078	Powder Coated	Side Panel	RoHS	No
26230-079	Powder Coated	Side Panel	RoHS	No
26230-113	Powder Coated	Side Panel	RoHS	No
26230-114	Powder Coated	Side Panel	RoHS	No
26230-115	Powder Coated	Side Panel	RoHS	No
26230-116	Powder Coated	Side Panel	RoHS	No
26230-117	Powder Coated	Side Panel	RoHS	No
26230-118	Powder Coated	Side Panel	RoHS	No
26230-119	Powder Coated	Side Panel	RoHS	No

Catalog Number	Finish	Type	Certifications	Quick Ship
26230-120	Powder Coated	Side Panel	RoHS	No
26230-121	Powder Coated	Side Panel	RoHS	No
26230-122	Powder Coated	Side Panel	RoHS	No
26230-123	Powder Coated	Side Panel	RoHS	No
26230-124	Powder Coated	Side Panel	RoHS	No
26230-125	Powder Coated	Side Panel	RoHS	No
26230-126	Powder Coated	Side Panel	RoHS	No
26230-127	Powder Coated	Side Panel	RoHS	No
26230-128	Powder Coated	Side Panel	RoHS	No
26230-129	Powder Coated	Side Panel	RoHS	No
26230-130	Powder Coated	Side Panel	RoHS	No
26230-131	Powder Coated	Side Panel	RoHS	No
26230-132	Powder Coated	Side Panel	RoHS	No
26230-133	Powder Coated	Side Panel	RoHS	No
26230-134	Powder Coated	Side Panel	RoHS	No
26230-135	Powder Coated	Side Panel	RoHS	No

## ADDITIONAL PRODUCT DETAILS

---

Optionally the quarter-turn fastener can be fitted with a side panel lock.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**