

2-2 Hole Corner Angle Bracket



FEATURES

Used to create metal frames with nVent CADDY Eristrut channels

SPECIFICATIONS

Table 1/3

Catalog Number	Article Number	E-Number	Material	Finish	Hole Size (HS)	Thickness (T)
ZWA205S6	388761	1522745	Stainless Steel 316 (EN 1.4401)		14 mm	6 mm
ZW205	313380	1523187	Steel	Hot-Dip Galvanized	14 mm	6 mm
ZWA205EG	387652		Steel	Electrogalvanized	14 mm	6 mm
ZWA205	387650	1522770	Steel	Hot-Dip Galvanized	14 mm	6 mm


Table 2/3

Catalog Number	Article Number	E-Number	A	B	Screw Included	Screw Diameter (Sc)
ZWA205S6	388761	1522745	102 mm	86 mm	No	
ZW205	313380	1523187	102 mm	86 mm	Yes	10 mm

CatalogNumber	Article Number	E-Number	A	B	Screw Included	ScrewDiameter (Sc)
ZWA205EG	387652		100 mm	95 mm	No	
ZWA205	387650	1522770	102 mm	86 mm	No	

Table 3/3			
Catalog Number	Article Number	E-Number	Screw Length (L)
ZWA205S6	388761	1522745	
ZW205	313380	1523187	25mm
ZWA205EG	387652		
ZWA205	387650	1522770	

DIAGRAMS

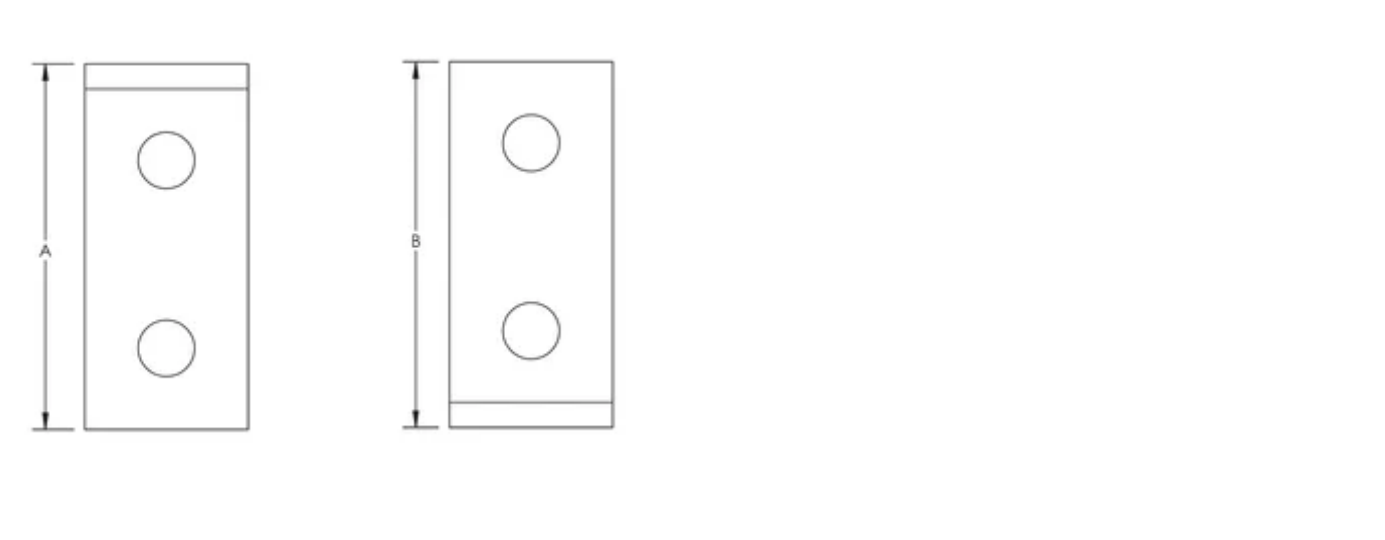

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

