


2000 Beam Clamp Kit

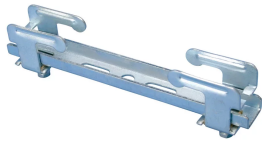

FEATURES

Light duty system

Includes clamp and U channel

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/3

Catalog Number	Article Number	E-Number	Length (L)	A	B	C
2300EG	570160	1500557	300mm	25 mm	25 mm	65 mm
2200EG	570140	1500555	200mm	25 mm	25 mm	65 mm
2400EG	570180	1500567	400mm	25 mm	25 mm	65 mm

Table 2/3

Catalog Number	Article Number	E-Number	D	E	Static Load 1 (F1)	Static Load 2 (F2)
2300EG	570160	1500557	25 mm	30.5 mm	1700N	490N

CatalogNumber	Article Number	E-Number	D	E	Static Load 1 (F1)	Static Load 2 (F2)
2200EG	570140	1500555	25 mm	30.5 mm	1700N	490N
2400EG	570180	1500567	25 mm	30.5 mm	1700N	490N

Table 3/3


Catalog Number	Article Number	E-Number	Static Load 3 (F3)
2300EG	570160	1500557	340N
2200EG	570140	1500555	340N
2400EG	570180	1500567	340N

Thickness (T): 2 mm
Screw Diameter (Sc): 6
Hole Size (HS): 11 mm
Height (H): 12 mm
Width (W): 25 mm
Torque (TQ): 30 N·m
Flange Thickness (FT): 11 mm Max

ADDITIONAL PRODUCT DETAILS

For a secure grip the channel must extend to the outer edge of each beam clamp.

DIAGRAMS

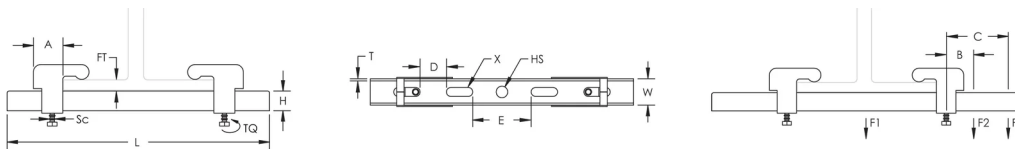

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

