


3000 U-Channel

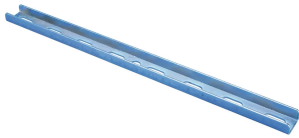

FEATURES

Medium duty U-channel for use with 3000 series beam clamps

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel


Table 1/2

Catalog Number	Article Number	E-Number	Length (L)	Height (H)	Width (W)	Thickness (T)
3004EG	570590	1511533	600mm	15 mm	30 mm	2.5 mm
3003EG	570580	1511532	500mm	15 mm	30 mm	2.5 mm

Table 2/2

Catalog Number	Article Number	E-Number	Hole Size (HS)	X	A	B
3004EG	570590	1511533	13 mm	10.5 x 25 mm	31.5 mm	25 mm
3003EG	570580	1511532	13 mm	10.5 x 25 mm	31.5 mm	25 mm

 DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

