


3000 U-Channel Beam Clamp

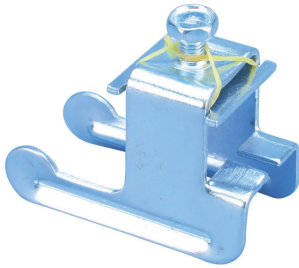

FEATURES

For use with 3000 series U-channels

Requires installation in pairs

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	Flange Thickness (FT)	A
3025EG	570500	1511520	Steel	Electrogalvanized	15 mm Max	40 mm

Table 2/2

Catalog Number	Article Number	E-Number	Screw Diameter (Sc)	Torque (TQ)
3025EG	570500	1511520	8	30 N·m

DIAGRAMS

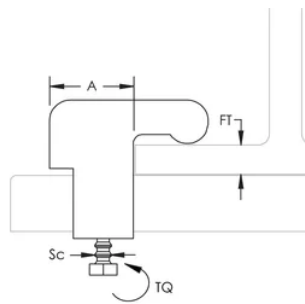

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

