

4G16H Twist Clip with 90° Plain Hole



CERTIFICATIONS



FEATURES

Provides an attachment for nVent CADDY Speed Link assemblies, wire, S-hooks, or chain from T-Grid

Fast, easy and secure twist-on installation

No tools required for installation

SPECIFICATIONS

Material: Spring Steel

Table 1/2


Catalog Number	Article Number	E-Number	Finish	Color	Hole Size (HS)	Flange Thickness (FT)
4G16H	170230	1500796	nVent CADDY Armour	Gray	6.4 mm	1.5 mm Max
4G16HWH	576950		Painted	White	6.4 mm	1.5 mm Max

Table 2/2

Catalog Number	Article Number	E-Number	T-Grid Size	Static Load
----------------	----------------	----------	-------------	-------------

4G16H	170230	1500796	24mm	180N
4G16HWH	576950		24mm	180N

DIAGRAMS

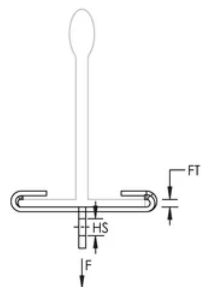

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

