

# 5000 Beam Clamp Kit



## FEATURES

C-Channel system

Includes beam clamp and channel

## SPECIFICATIONS

**Finish:** Hot-Dip Galvanized

**Material:** Steel

Table 1/2

Catalog Number	Article Number	E-Number	Length (L)	Channel Type	Rod Size (RS)	Flange Thickness (FT)
5300HD	335000	1500624	300mm	E5	10	3 - 30 mm
5400HD	335010	1500625	400mm	E5	10	3 - 30 mm
5500HD	335020	1500626	500mm	E5	10	3 - 30 mm
5600HD	335030	1500627	600mm	E5	10	3 - 30 mm
5800HD	335040	1500628	800mm	E5	10	3 - 30 mm


Table 2/2

Catalog Number	Article Number	E-Number	Torque (TQ)
----------------	----------------	----------	-------------

5300HD	335000	1500624	30 N·m
5400HD	335010	1500625	30 N·m
5500HD	335020	1500626	30 N·m
5600HD	335030	1500627	30 N·m
5800HD	335040	1500628	30 N·m

A	Static Load 1 F1	Static Load 2 F2
100 mm	3500 N	850 N
200 mm	1750 N	400 N
300 mm	1100 N	250 N
400 mm	800 N	200 N
500 mm	700 N	175 N
600 mm	500 N	125 N

### DIAGRAMS

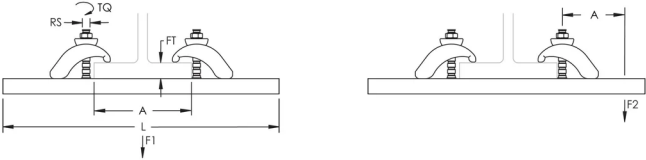

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

