

BC-M Conduit to Beam Clamp



CERTIFICATIONS



FEATURES

Easy installation to beam flanges

Eliminates offset bending conduit

Conduit clip rotates 360 degrees

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/2


Catalog Number	Article Number	E-Number	Outer Diameter (OD)	Flange Thickness (FT)	Torque (TQ)	Static Load
EBC6M	172580		14 - 18 mm	16 mm Max	3 N·m	450N
EBC812M	160200	1500662	18 - 30 mm	16 mm Max	3 N·m	450N
EBC16M	172590	1500663	23.4 - 35 mm	16 mm Max	3 N·m	450N

CatalogNumber	Article Number	E-Number	Outer Diameter (OD)	Flange Thickness (FT)	Torque (TQ)	Static Load
EBC20M	172600	1500664	35 - 42 mm	16 mm Max	3 N·m	450N
EBC24M	172610		42 - 50 mm	16 mm Max	3 N·m	450N
EBC32M	172620		50 - 60 mm	16 mm Max	3 N·m	450N

Table 2/2

Catalog Number	Article Number	E-Number	Certifications
EBC6M	172580		
EBC812M	160200	1500662	ITB
EBC16M	172590	1500663	ITB
EBC20M	172600	1500664	ITB
EBC24M	172610		ITB
EBC32M	172620		ITB

DIAGRAMS

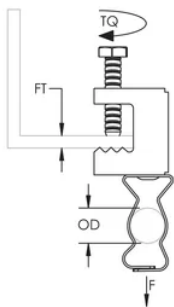

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

