


BC-MSM Conduit to Beam Clamp, Side Mount

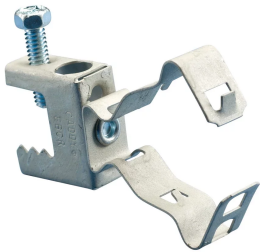

CERTIFICATIONS



FEATURES

Easy installation to beam flanges

Eliminates offset bending conduit

Conduit clip rotates 360 degrees

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/2


Catalog Number	Article Number	E-Number	Outer Diameter (OD)	Flange Thickness (FT)	Torque (TQ)	Static Load
EBC6MSM	172650		14 - 18 mm	16 mm Max	3 N·m	110N
EBC812MSM	160180	1500710	18 - 30 mm	16 mm Max	3 N·m	110N
EBC16MSM	172660		23.4 - 35 mm	16 mm Max	3 N·m	110N

CatalogNumber	Article Number	E-Number	Outer Diameter (OD)	Flange Thickness (FT)	Torque (TQ)	Static Load
EBC20MSM	172670	1500712	35 - 42 mm	16 mm Max	3 N·m	110N
EBC24MSM	172680		42 - 50 mm	16 mm Max	3 N·m	110N
EBC32MSM	172690		50 - 60 mm	16 mm Max	3 N·m	110N

Table 2/2

Catalog Number	Article Number	E-Number	Certifications
EBC6MSM	172650		
EBC812MSM	160180	1500710	ITB
EBC16MSM	172660		ITB
EBC20MSM	172670	1500712	ITB
EBC24MSM	172680		ITB
EBC32MSM	172690		ITB

DIAGRAMS

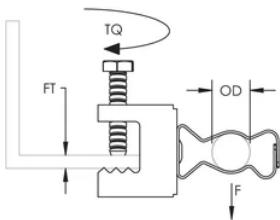

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

