

EER-Ti/T Trapezoidal Deck Threaded Rod Hanger



CERTIFICATIONS



FEATURES

Supports threaded rod

Thread impression for simple installation

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/2

Catalog Number	Article Number	E-Number	Hole Size (HS)	Hole Type	Flange Thickness (FT)	Drill Bit Diameter
EERTIM10	173140	1522844	10 mm	Threaded	0.8 - 3 mm	7mm
EERTIM6	173120	1500761	6 mm	Threaded	0.8 - 3 mm	7mm

CatalogNumber	Article Number	E-Number	Hole Size (HS)	Hole Type	Flange Thickness (FT)	Drill Bit Diameter
EERTIM8	173130	1500762	8 mm	Threaded	0.8 - 3 mm	7mm


Table 2/2

Catalog Number	Article Number	E-Number	Static Load 1 (F1)	Static Load 2 (F2)	Certifications
EERTIM10	173140	1522844	450N	900N	ITB
EERTIM6	173120	1500761	450N	900N	
EERTIM8	173130	1500762	450N	900N	ITB

ADDITIONAL PRODUCT DETAILS

Static Load 1 represents 0.8 - 2.0 mm flange thickness. Static Load 2 represents 2.0 - 3.0 mm flange thickness.

DIAGRAMS

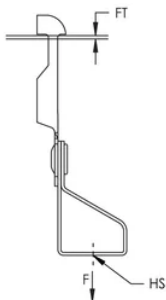

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

