

EM-P Conduit to Flange Clip



CERTIFICATIONS



FEATURES

Requires only a hammer to install

Available for EMT, rigid, IMT and aluminum conduit

Will pivot thru 360°

SPECIFICATIONS

Finish: nVent CADDY Armour


Material: Spring Steel

Table 1/1

Catalog Number	Article Number	E-Number	Outer Diameter (OD)	Flange Thickness (FT)	Ultimate Static Load (F)	Certifications
12P24	175110	1500642	22 - 30 mm	3 - 8 mm	110N	
16P24	175140	1500643	30 - 35 mm	3 - 8 mm	110N	
8P24	172150	1500641	18 - 22 mm	3 - 8 mm	110N	ITB

CatalogNumber	Article Number	E-Number	Outer Diameter (OD)	Flange Thickness (FT)	Ultimate Static Load (F)	Certifications
12P58	175120	1500649	22 - 30 mm	8 - 14 mm	110N	
16P58	175150	1500650	30 - 35 mm	8 - 14 mm	110N	
8P58	172160	1500648	18 - 22 mm	8 - 14 mm	110N	ITB
8P912	175100	1500654	18 - 22 mm	14 - 20 mm	110N	ITB
12P912	175130	1500655	22 - 30 mm	14 - 20 mm	110N	
16P912	175160	1500656	30 - 35 mm	14 - 20 mm	110N	

DIAGRAMS

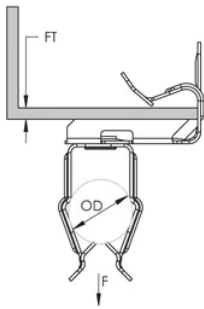

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

