

Hammer-On Flange Clip, Bottom Mount



CERTIFICATIONS



FEATURES

Can be used to support boxes, fixtures or other applications from beam flanges

Assorted attachment points provided to reduce inventory

Requires only a hammer to install

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	Flange Thickness (FT)	Rod Size (RS)
EM24	170050	1511450	Spring Steel	nVent CADDY Armour	3 - 8 mm	6
EM24S1	179720	1500603	Stainless Steel 301 (EN 1.4310)		3 - 8 mm	6
EM24SP25	172170	1511451	Spring Steel	nVent CADDY Armour	3 - 8 mm	6
EM58	170060	1511452	Spring Steel	nVent CADDY Armour	8 - 14 mm	6


CatalogNumber	Article Number	E-Number	Material	Finish	Flange Thickness (FT)	Rod Size (RS)
EM58R5	191027	1500698	Spring Steel	nVent CADDY Armour	8 - 14 mm	6
EM58S1	179730	1500609	Stainless Steel 301 (EN 1.4310)		8 - 14 mm	6
EM58SP25	172180	1511453	Spring Steel	nVent CADDY Armour	8 - 14 mm	6
EM912	170070	1511454	Spring Steel	nVent CADDY Armour	14 - 20 mm	6
EM912S1	179740	1500615	Stainless Steel 301 (EN 1.4310)		14 - 20 mm	6
EM912SP25	175760	1511455	Spring Steel	nVent CADDY Armour	14 - 20 mm	6
EM1318	170075		Spring Steel	nVent CADDY Armour	21 - 28 mm	6

Table 2/2

Catalog Number	Article Number	E-Number	Static Load 1 (F1)	Static Load 2 (F2)	Static Load 3 (F3)	Certifications
EM24	170050	1511450	450N	110N	330N	CE, 4H, EM, EBC, ITB
EM24S1	179720	1500603	200N	110N	200N	
EM24SP25	172170	1511451	450N	110N	330N	CE, 4H, EM, EBC
EM58	170060	1511452	450N	110N	330N	CE, 4H, EM, EBC, ITB
EM58R5	191027	1500698	450N	110N	330N	CE, 4H, EM, EBC
EM58S1	179730	1500609	200N	110N	200N	
EM58SP25	172180	1511453	450N	110N	330N	CE, 4H, EM, EBC
EM912	170070	1511454	450N	110N	330N	CE, 4H, EM, EBC, ITB
EM912S1	179740	1500615	200N	110N	200N	

CatalogNumber	Article Number	E-Number	Static Load 1 (F1)	Static Load 2 (F2)	Static Load 3 (F3)	Certifications
EM912SP25	175760	1511455	450N	110N	330N	CE, 4H, EM, EBC
EM1318	170075		450N	110N	330N	cUL, UL

DIAGRAMS

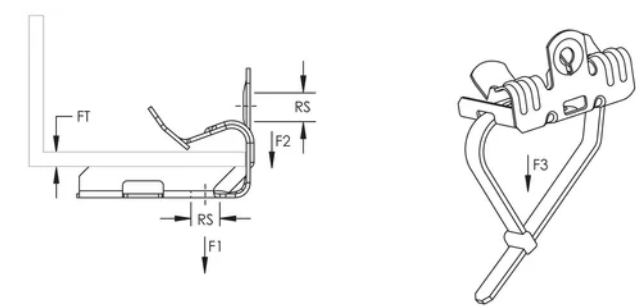

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

