

Internal Strut Beam Clamp with Bolt



FEATURES

U-shaped clip for clamping the back of strut channel to a beam

Hex bolt included

Requires installation in pairs

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	Flange Thickness (FT)	Width (W)
ZT606HDEG	313270	1500651	Steel	Hot-Dip Galvanized, Electrogalvanized	28 mm Max	30 mm

Table 2/2


Catalog Number	Article Number	E-Number	Screw Diameter (Sc)	Static Load
ZT606HDEG	313270	1500651	10	2900N

ADDITIONAL PRODUCT DETAILS

Static Load is based on one pair of Strut Beam Clamps.

Include strut channel thickness when calculating flange thickness.

DIAGRAMS

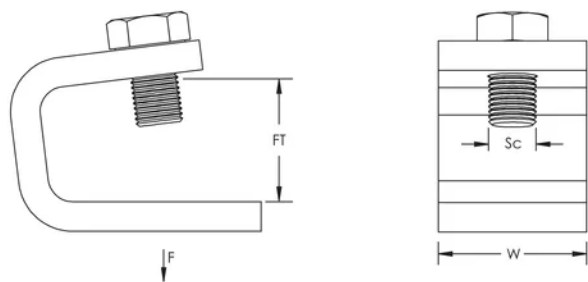

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

