

nVent CADDY Rod Lock Anchor Screw



CERTIFICATIONS



FEATURES

For use with concrete and solid brick

Prefabricated assemblies easily lift and lock into place, helping to save time and money

Works with slightly damaged threads and minor burrs on the threaded rod

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel


Table 1/2

Catalog Number	Article Number	E-Number	Rod Size (RS)	B	C	Length (L)
CRLAM8EG	390009	1507696	8	32 mm	22 mm	72mm
CRLAM10EG	390010	1507697	10	32 mm	22 mm	72mm

Table 2/2

Catalog Number	Article Number	E-Number	Drill Bit Diameter	Drill Hole Depth	Static Load	Certifications
CRLAM8EG	390009	1507696	8mm	50mm	2900N	ITB
CRLAM10EG	390010	1507697	8mm	50mm	2900N	FM Approved, Pipe Hanger Components, ITB

DIAGRAMS

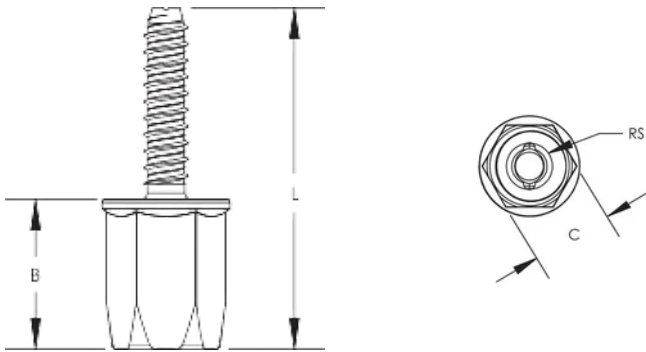

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

