

# nVent CADDY Speed Link SLDM with Hook



## CERTIFICATIONS



## FEATURES

Complete system includes wire, locking device and pre-assembled hook end fitting

Ideal for supporting lighting, ductwork and other installation projects

Sleek, low-profile locking device reduces visual impact

Keyless locking device is adjustable even after installation

## SPECIFICATIONS

|                                   |                   |
|-----------------------------------|-------------------|
| <b>Wire Rope Diameter:</b>        | 1.5 mm            |
| <b>Static Load Safety Factor:</b> | 5:1               |
| <b>Finish:</b>                    | Electrogalvanized |
| <b>Material:</b>                  | Steel             |

Table 1/2

| Catalog Number | Article Number | E-Number | Wire Rope Length | A       | B       | C      |
|----------------|----------------|----------|------------------|---------|---------|--------|
| SLDM615L2      | 196029         | 1568184  | 2m               | 58.4 mm | 22.9 mm | 6.4 mm |

| CatalogNumber | Article Number | E-Number | Wire Rope Length | A       | B       | C      |
|---------------|----------------|----------|------------------|---------|---------|--------|
| SLDM615L1     | 196028         | 1568183  | 1m               | 58.4 mm | 22.9 mm | 6.4 mm |

| Table 2/2      |                |          |             |
|----------------|----------------|----------|-------------|
| Catalog Number | Article Number | E-Number | Static Load |
| SLDM615L2      | 196029         | 1568184  | 195N        |
| SLDM615L1      | 196028         | 1568183  | 195N        |

Rod Size (RS):

6

Length (L):

7mm


Width (W):

9.2 mm

Height (H):

24.5 mm

DIAGRAMS

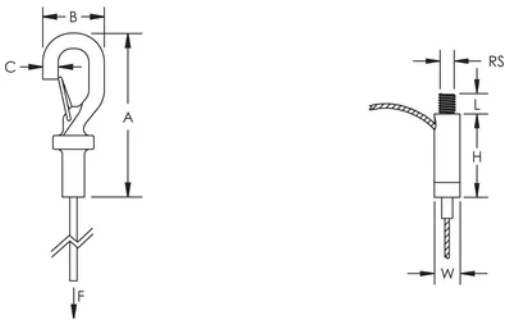

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

