

nVent CADDY Speed Link SLK with Angle Bracket



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled angle bracket end fitting

Ideal for attaching to concrete, steel or wood surfaces

Simple alternative to jack chain and additional hardware

SPECIFICATIONS

Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Zinc Alloy;Polypropylene
Complies With:	SMACNA HVAC-DCS

Table 1/3

Catalog Number	Article Number	E-Number	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)
SLK15L1AB	196500	1568200	1.5 mm	1m	22.6 mm	7.1 mm

CatalogNumber	Article Number	E-Number	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)
SLK15L2AB	196501	1568201	1.5 mm	2m	22.6 mm	7.1 mm
SLK15L3AB	196502	1568202	1.5 mm	3m	22.6 mm	7.1 mm
SLK15L5AB	196503	1568203	1.5 mm	5m	22.6 mm	7.1 mm
SLK2L2AB	196529	1568204	2 mm	2m	22.6 mm	7.1 mm
SLK2L3AB	196530	1568205	2 mm	3m	22.6 mm	7.1 mm
SLK2L5AB	196531	1568206	2 mm	5m	22.6 mm	7.1 mm
SLK3L10AB	196716	1568119	3 mm	10m	22.6 mm	7.1 mm
SLK3L2AB	196713	1568121	3 mm	2m	22.6 mm	7.1 mm
SLK3L5AB	196715	1568123	3 mm	5m	22.6 mm	7.1 mm

Table 2/3


Catalog Number	Article Number	E-Number	Height (H)	Width (W)	Thickness (T)	Angle (a)
SLK15L1AB	196500	1568200	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L2AB	196501	1568201	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L3AB	196502	1568202	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L5AB	196503	1568203	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L2AB	196529	1568204	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L3AB	196530	1568205	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L5AB	196531	1568206	55 mm	19 mm	12.5 mm	90 ° Max

CatalogNumber	Article Number	E-Number	Height (H)	Width (W)	Thickness (T)	Angle (a)
SLK3L10AB	196716	1568119	62 mm	24 mm	16 mm	90 ° Max
SLK3L2AB	196713	1568121	62 mm	24 mm	16 mm	90 ° Max
SLK3L5AB	196715	1568123	62 mm	24 mm	16 mm	90 ° Max

Table 3/3

Catalog Number	Article Number	E-Number	Static Load	Certifications
SLK15L1AB	196500	1568200	195N	ITB, UL, cUL
SLK15L2AB	196501	1568201	195N	ITB, UL, cUL
SLK15L3AB	196502	1568202	195N	cUL, ITB, UL
SLK15L5AB	196503	1568203	195N	ITB, UL, cUL
SLK2L2AB	196529	1568204	440N	ITB, UL, cUL
SLK2L3AB	196530	1568205	440N	ITB, UL, cUL
SLK2L5AB	196531	1568206	440N	ITB, UL, cUL
SLK3L10AB	196716	1568119	890N	
SLK3L2AB	196713	1568121	890N	
SLK3L5AB	196715	1568123	890N	

DIAGRAMS

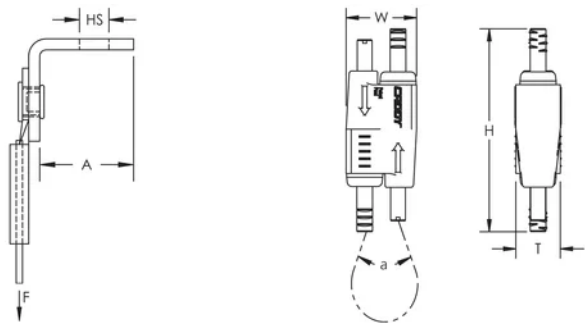

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

