


nVent CADDY Speed Link SLK with Hammer-On Flange Clip



CERTIFICATIONS

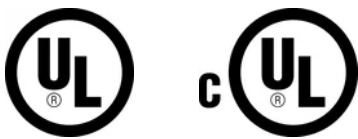

FEATURES

Complete system includes wire, locking device and pre-assembled nVent CADDY Hammer-On Flange Clip end fitting

Installs with just a hammer

Fits most beams

SPECIFICATIONS

Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Polypropylene;Zinc Alloy
Complies With:	SMACNA HVAC-DCS

Table 1/1

Catalog Number	Article Number	E-Number	Wire Rope Diameter	Wire Rope Length	Flange Thickness (FT)	Static Load
SLK15L34H24	196506	1568219	1.5 mm	3m	3 - 8 mm	195N

CatalogNumber	Article Number	E-Number	Wire Rope Diameter	Wire Rope Length	Flange Thickness (FT)	Static Load
SLK2L34H24	196535	1568221	2 mm	3m	3 - 8 mm	440N
SLK15L34H58	196507	1568220	1.5 mm	3m	8 - 14 mm	195N
SLK2L34H58	196536	1568222	2 mm	3m	8 - 14 mm	440N


Thickness (T): 12.5 mm

Width (W): 19 mm

Height (H): 55 mm

Angle (a): 90 ° Max

DIAGRAMS

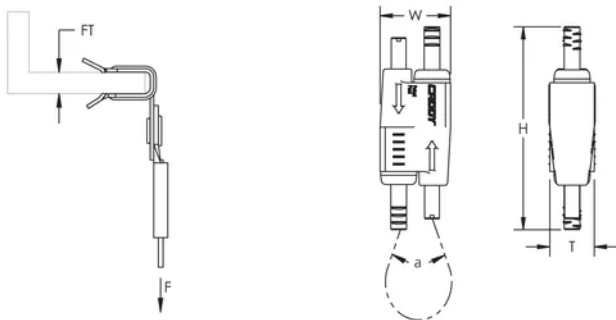

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

