

# nVent CADDY Speed Link SLK with Threaded Stud End



## CERTIFICATIONS



## FEATURES

Complete system includes wire, locking device and pre-assembled threaded stud end fitting

Attaches to structures with threaded anchors or devices with threaded hole

Connects directly to threaded devices in trapeze assemblies, light fixtures, HVAC assemblies or signage

## SPECIFICATIONS

<b>Static Load Safety Factor:</b>	5:1
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;Polypropylene;Zinc Alloy
<b>Complies With:</b>	SMACNA HVAC-DCS

Table 1/3

Catalog Number	Article Number	E-Number	Wire Rope Diameter	Wire Rope Length	Rod Size (RS)	Screw Length (L)
SLK15L2SEM8	196567	1568250	1.5 mm	2m	8	45mm

CatalogNumber	Article Number	E-Number	Wire Rope Diameter	Wire Rope Length	Rod Size (RS)	Screw Length (L)
SLK15L3SEM6	196568	1568251	1.5 mm	3m	6	25mm
SLK15L1SEM6	196564	1568247	1.5 mm	1m	6	25mm
SLK2L5SEM8	196563	1568258	2 mm	5m	8	45mm
SLK2L3SEM8	196561	1568256	2 mm	3m	8	45mm
SLK2L5SEM6	196562	1568257	2 mm	5m	6	25mm
SLK2L2SEM8	196559	1568254	2 mm	2m	8	45mm
SLK15L1SEM8	196565	1568248	1.5 mm	1m	8	45mm
SLK15L2SEM6	196566	1568249	1.5 mm	2m	6	25mm
SLK15L3SEM8	196570	1568252	1.5 mm	3m	8	45mm

Table 2/3


Catalog Number	Article Number	E-Number	Height (H)	Width (W)	Thickness (T)	Angle (a)
SLK15L2SEM8	196567	1568250	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L3SEM6	196568	1568251	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L1SEM6	196564	1568247	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L5SEM8	196563	1568258	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L3SEM8	196561	1568256	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L5SEM6	196562	1568257	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L2SEM8	196559	1568254	55 mm	19 mm	12.5 mm	90 ° Max

CatalogNumber	Article Number	E-Number	Height (H)	Width (W)	Thickness (T)	Angle (a)
SLK15L1SEM8	196565	1568248	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L2SEM6	196566	1568249	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L3SEM8	196570	1568252	55 mm	19 mm	12.5 mm	90 ° Max

Table 3/3

Catalog Number	Article Number	E-Number	Static Load
SLK15L2SEM8	196567	1568250	195N
SLK15L3SEM6	196568	1568251	195N
SLK15L1SEM6	196564	1568247	195N
SLK2L5SEM8	196563	1568258	440N
SLK2L3SEM8	196561	1568256	440N
SLK2L5SEM6	196562	1568257	440N
SLK2L2SEM8	196559	1568254	440N
SLK15L1SEM8	196565	1568248	195N
SLK15L2SEM6	196566	1568249	195N
SLK15L3SEM8	196570	1568252	195N

DIAGRAMS

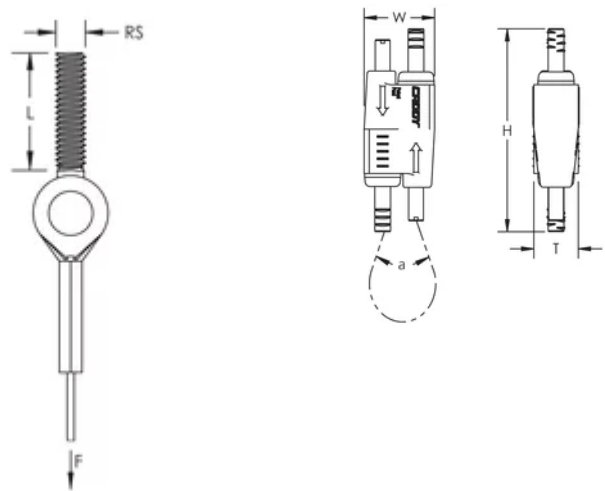

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

