

# OCDC Deck Hanger



## FEATURES

Provide a mobile mounting hole

Attaches to decking without having to drill or punch holes

Secured between the overlap of two steel sheets

## SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	Hole Size (HS)	Flange Thickness (FT)
OCDC68MM	160700	1511710	Steel	nVent CADDY Armour	6.8 mm	1.0 - 2.5 mm

Table 2/2

Catalog Number	Article Number	E-Number	B	C	X	Static Load
OCDC68MM	160700	1511710	54 mm	46 mm	13 x 8.5 mm	400N

DIAGRAMS

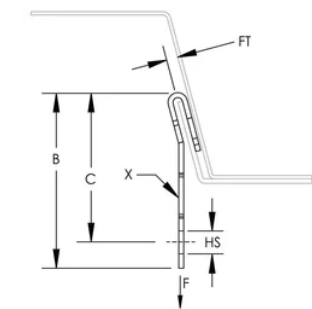

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

