

# Pipe/Cable Clamp



## FEATURES

Captive threaded stud minimizes the need for additional hardware

With the UNICBAND Sign Support Bracket and Fixoband Strap, attachments to pipe and pole can be made

## SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	NB/DN	Outer Diameter (OD)
CR037HD	336300	1511350	Steel	Hot-Dip Galvanized	10	16 - 20 mm
CR037S4	336400		Stainless Steel 304 (EN 1.4301)		10	16 - 20 mm
CR050HD	336310	1511351	Steel	Hot-Dip Galvanized	15	20 - 25 mm
CR050S4	336410	1500499	Stainless Steel 304 (EN 1.4301)		15	20 - 25 mm
CR075HD	336320	1511352	Steel	Hot-Dip Galvanized	20	26.9 - 31.8 mm
CR075S4	336420	1500500	Stainless Steel 304 (EN 1.4301)		20	26.9 - 31.8 mm


CatalogNumber	Article Number	E-Number	Material	Finish	NB/DN	Outer Diameter (OD)
CR087HD	336322		Steel	Hot-Dip Galvanized		32 - 34 mm
CR100HD	336330	1511353	Steel	Hot-Dip Galvanized	25	33.7 - 38 mm
CR100S4	336430	1500489	Stainless Steel 304 (EN 1.4301)		25	33.7 - 38 mm
CR125HD	336340	1511354	Steel	Hot-Dip Galvanized	32	40.0 - 44.5 mm
CR125S4	336440		Stainless Steel 304 (EN 1.4301)		32	40.0 - 44.5 mm
CR150HD	336350	1511355	Steel	Hot-Dip Galvanized	40	47 - 51 mm
CR150S4	336450	1500508	Stainless Steel 304 (EN 1.4301)		40	47 - 51 mm
CR200HD	336360	1511356	Steel	Hot-Dip Galvanized	50	59.2 - 63.5 mm
CR200S4	336460	1500490	Stainless Steel 304 (EN 1.4301)		50	59.2 - 63.5 mm

Table 2/2

Catalog Number	Article Number	E-Number	Width (W)	Static Load 1 (F1)	Static Load 2 (F2)
CR037HD	336300	1511350	16 mm	125N	550N
CR037S4	336400		16 mm	125N	550N
CR050HD	336310	1511351	16 mm	125N	550N
CR050S4	336410	1500499	16 mm	125N	550N
CR075HD	336320	1511352	16 mm	125N	550N
CR075S4	336420	1500500	16 mm	125N	550N
CR087HD	336322		16 mm	125N	550N

Catalog Number	Article Number	E-Number	Width (W)	Static Load 1 (F1)	Static Load 2 (F2)
CR100HD	336330	1511353	20 mm	250N	550N
CR100S4	336430	1500489	20 mm	250N	550N
CR125HD	336340	1511354	20 mm	250N	550N
CR125S4	336440		20 mm	250N	550N
CR150HD	336350	1511355	20 mm	250N	550N
CR150S4	336450	1500508	20 mm	250N	550N
CR200HD	336360	1511356	20 mm	250N	550N
CR200S4	336460	1500490	20 mm	250N	550N

## DIAGRAMS

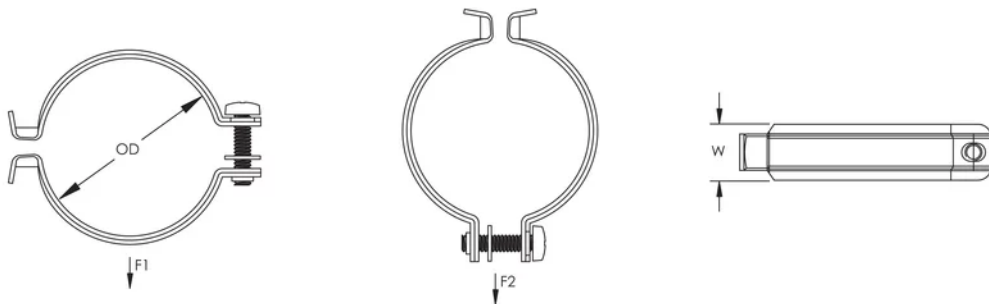

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

