

Push In Conduit Clamp



FEATURES

Push-in installation of conduit

Eliminates need for offset bending conduit

May be used for either vertical or horizontal installations

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/2


Catalog Number	Article Number	E-Number	Outer Diameter (OD)	Hole Size (HS)	Hole Type	Ultimate Static Load 1 (F1)
12P	171150	1500667	22 - 30 mm	7 mm	Plain	110N
16P	171170	1500668	30 - 35 mm	7 mm	Plain	110N
8P	171130		18 - 22 mm	7 mm	Plain	110N

Table 2/2

Catalog Number	Article Number	E-Number	Ultimate Static Load 2 (F2)
12P	171150	1500667	65N

Catalog Number	Article Number	E-Number	Ultimate Static Load 2 (F2)
16P	171170	1500668	65N
8P	171130		65N

DIAGRAMS

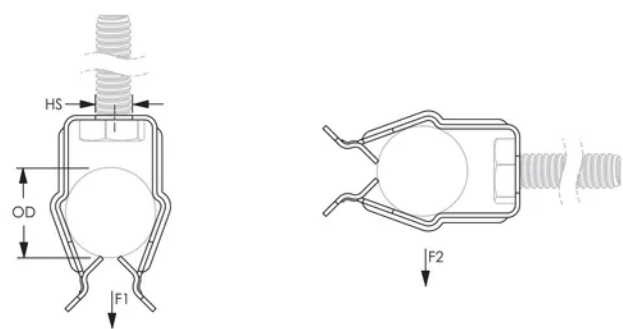

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

