

RING FRF /1 Single Pipe Clip with Plug



FEATURES

Hammer in plastic clip to hold one pipe/conduit

Fix into drilled hole in brick or concrete

SPECIFICATIONS

Material: Polyamide

Table 1/2


Catalog Number	Article Number	E-Number	Outer Diameter (OD)	Length (L)	Width (W)	Diameter (Ø)
FRF028	571190	1506136	28 mm	30mm	20 mm	9.8 mm
FRF025	571180	1506135	25 mm	30mm	20 mm	9.8 mm
FRF022	571170	1506134	22 mm	30mm	20 mm	9.8 mm
FRF014	571130	1506130	14 mm	30mm	20 mm	9.8 mm
FRF020	571160	1506133	20 mm	30mm	20 mm	9.8 mm
FRF018	571150	1506132	18 mm	30mm	20 mm	9.8 mm

CatalogNumber	Article Number	E-Number	Outer Diameter (OD)	Length (L)	Width (W)	Diameter (Ø)
FRF016	571140	1506131	16 mm	30mm	20 mm	9.8 mm

Table 2/2

Catalog Number	Article Number	E-Number	Drill Bit Diameter
FRF028	571190	1506136	8mm
FRF025	571180	1506135	8mm
FRF022	571170	1506134	8mm
FRF014	571130	1506130	8mm
FRF020	571160	1506133	8mm
FRF018	571150	1506132	8mm
FRF016	571140	1506131	8mm

DIAGRAMS

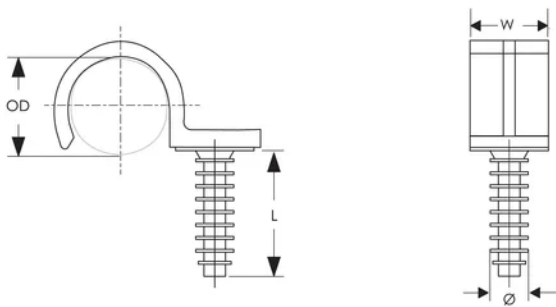

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

