


Saddle Washer

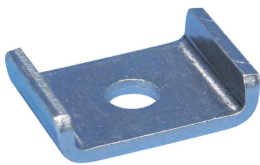

FEATURES

U-shaped wrap around washer

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	E-Number	Material	Finish	Hole Size (HS)	Thickness (T)
PLN13HD	589949		Steel	Hot-Dip Galvanized	13 mm	3 mm
PLN10	589930	1522661	Steel	Electrogalvanized	10.5 mm	3 mm
PLN13	589940		Steel	Electrogalvanized	13 mm	3 mm
PLN8	589925	1522657	Steel	Electrogalvanized	8.4 mm	3 mm
PLN11S6	589928		Stainless Steel 316 (EN 1.4401)		11 mm	3 mm

Table 2/2

Catalog Number	Article Number	E-Number	A	B
PLN13HD	589949		42 mm	30 mm

Catalog Number	Article Number	E-Number	A	B
PLN10	589930	1522661	42 mm	30 mm
PLN13	589940		42 mm	30 mm
PLN8	589925	1522657	42 mm	30 mm
PLN11S6	589928		42 mm	50 mm

DIAGRAMS

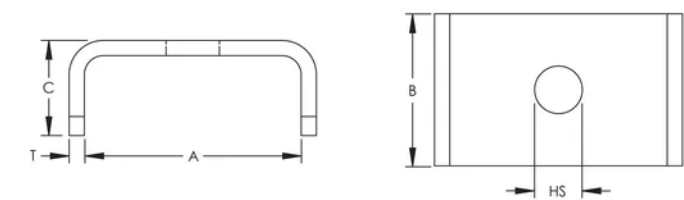

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

