

# SC Cable Snap Clip



## FEATURES

Easily supports cable and plastic conduit from flanges

Requires only a hammer to install

## SPECIFICATIONS

**Finish:** nVent CADDY Armour

**Material:** Spring Steel


Table 1/1

Catalog Number	Article Number	E-Number	Flange Thickness (FT)	Outer Diameter (OD)	Thickness (T)
24SC1011	187550	1511144	2 - 4 mm	10 - 11 mm	0.6 mm
24SC1214	187570	1511146	2 - 4 mm	12 - 14 mm	0.6 mm
24SC1518	187590	1511148	2 - 4 mm	15 - 18 mm	0.6 mm
24SC1518R25	191003	1500595	2 - 4 mm	15 - 18 mm	0.6 mm
24SC1924	187610	1511150	2 - 4 mm	19 - 24 mm	0.6 mm
24SC1924R25	191004	1500596	2 - 4 mm	19 - 24 mm	0.6 mm

Catalog Number	Article Number	E-Number	Flange Thickness (FT)	Outer Diameter (OD)	Thickness (T)
24SC2530	187630	1511152	2 - 4 mm	25 - 30 mm	0.6 mm
24SC2530R25	191005	1500597	2 - 4 mm	25 - 30 mm	0.6 mm
24SC67	187510	1511140	2 - 4 mm	6 - 7 mm	0.6 mm
24SC78	187710	1500586	2 - 4 mm	7 - 8 mm	0.6 mm
24SC89	187530	1511142	2 - 4 mm	8 - 9 mm	0.6 mm
24SC910	187750		2 - 4 mm	9 - 10 mm	0.6 mm
47SC1011	187540	1511164	4 - 7 mm	10 - 11 mm	0.6 mm
47SC1214	187560	1511166	4 - 7 mm	12 - 14 mm	0.6 mm
47SC1518	187580	1511168	4 - 7 mm	15 - 18 mm	0.6 mm
47SC1518R25	191009	1500600	4 - 7 mm	15 - 18 mm	0.6 mm
47SC1924	187600	1511170	4 - 7 mm	19 - 24 mm	0.6 mm
47SC1924R25	191010	1500601	4 - 7 mm	19 - 24 mm	0.6 mm
47SC2530	187620	1511172	4 - 7 mm	25 - 30 mm	0.6 mm
47SC2530R25	191011	1500602	4 - 7 mm	25 - 30 mm	0.6 mm
47SC67	187500	1511160	4 - 7 mm	6 - 7 mm	0.6 mm
47SC78	187720		4 - 7 mm	7 - 8 mm	0.6 mm
47SC89	187520	1511162	4 - 7 mm	8 - 9 mm	0.6 mm
47SC910	187760		4 - 7 mm	9 - 10 mm	0.6 mm

Catalog Number	Article Number	E-Number	Flange Thickness (FT)	Outer Diameter (OD)	Thickness (T)
812SC1011	187660	1511184	8 - 12 mm	10 - 11 mm	0.6 mm
812SC1214	187670	1511186	8 - 12 mm	12 - 14 mm	0.6 mm
812SC1518	187680	1511188	8 - 12 mm	15 - 18 mm	0.6 mm
812SC1518R25	191015		8 - 12 mm	15 - 18 mm	0.6 mm
812SC1924	187690	1511190	8 - 12 mm	19 - 24 mm	0.6 mm
812SC1924R25	191016	1500606	8 - 12 mm	19 - 24 mm	0.6 mm
812SC2530	187700	1511192	8 - 12 mm	25 - 30 mm	0.6 mm
812SC2530R25	191017	1500607	8 - 12 mm	25 - 30 mm	0.6 mm
812SC67	187640	1511180	8 - 12 mm	6 - 7 mm	0.6 mm
812SC78	187730		8 - 12 mm	7 - 8 mm	0.6 mm
812SC89	187650	1511182	8 - 12 mm	8 - 9 mm	0.6 mm
812SC910	187770		8 - 12 mm	9 - 10 mm	0.6 mm

## DIAGRAMS

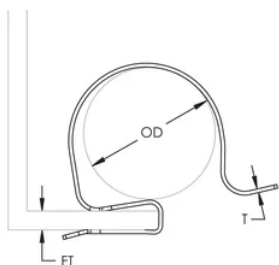

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

