

Snap Close Conduit/Pipe Clamp



The nVent CADDY Snap Close Conduit Clamps (M-Series) are a fast and efficient method to secure conduit branch circuits for electrical installations. The M-Series is designed to provide positional consistency in application by eliminating conduit offset as well as maintain spacing entering electrical boxes. Increase installation efficiency by utilizing our comprehensive conduit range for your next electrical project.

CERTIFICATIONS



FEATURES

May be used for either vertical or horizontal installations

Eliminates need for offset bending conduit

Finger closure, no tools required

Locking design has greater resistance to twisting loads and is stronger than any on the market

Low profile locking tabs and smooth gripping dimples remove the possibility of scrapes

812M and 16M feature double tabs to center conduit, increase range and holding power and prevent conduit from sliding

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	E-Number	Material	Finish	Outer Diameter (OD)	Hole Size (HS)
12MS1	179910		Stainless Steel 301 (EN 1.4310)		22 - 30 mm	7 mm
16M	170100	1500739	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	7 mm

CatalogNumber	Article Number	E-Number	Material	Finish	Outer Diameter (OD)	Hole Size (HS)
20M	170110	1500740	Spring Steel	nVent CADDY Armour	35 - 42 mm	7 mm
24M	170120		Spring Steel	nVent CADDY Armour	42 - 50 mm	7 mm
32M	170130		Spring Steel	nVent CADDY Armour	50 - 60 mm	7 mm
6M	170790		Spring Steel	nVent CADDY Armour	14 - 18 mm	7 mm
812M	177130	1511480	Spring Steel	nVent CADDY Armour	18 - 30 mm	7 mm
8MS1	179900		Stainless Steel 301 (EN 1.4310)		18 - 22 mm	7 mm

Table 2/2

Catalog Number	Article Number	E-Number	Hole Type	Static Load 1 (F1)	Static Load 2 (F2)	Certifications
12MS1	179910		Plain	440N	110N	
16M	170100	1500739	Plain	440N	110N	cUL, UL
20M	170110	1500740	Plain	440N	110N	UL, cUL
24M	170120		Plain	440N	110N	UL, cUL
32M	170130		Plain	440N	110N	cUL, UL
6M	170790		Plain	440N	110N	cUL, UL
812M	177130	1511480	Plain	440N	110N	cUL, UL
8MS1	179900		Plain	440N	110N	

DIAGRAMS

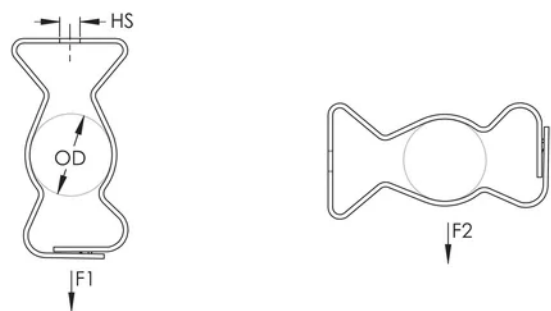

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

