

Strut Beam Clip



FEATURES

Beam Clip for clamping the open side of strut to a beam

Suitable for all strut channels

Requires installation in pairs

Structural attachment to beams to support nVent CADDY Eristrut

FM® Specification Tested

SPECIFICATIONS

Table 1/3

Catalog Number	Article Number	E-Number	Material	Finish	Flange Thickness (FT)	Hole Size (HS)
ZT605HD	313260	1500671	Steel	Hot-Dip Galvanized	16 mm Max	13 mm
ZTA605	388080	1500635	Steel	Hot-Dip Galvanized	16 mm Max	13 mm
ZTA605S6	387190	1500617	Stainless Steel 316 (EN 1.4401)		16 mm Max	13 mm

Table 2/3

Catalog Number	Article Number	E-Number	Length (L)	Thickness (T)	Width (W)	Static Load
ZT605HD	313260	1500671	49mm	6 mm	40 mm	2040N

CatalogNumber	Article Number	E-Number	Length (L)	Thickness (T)	Width (W)	Static Load
ZTA605	388080	1500635	49mm	6 mm	40 mm	2040N
ZTA605S6	387190	1500617	49mm	6 mm	40 mm	2040N


Table 3/3

Catalog Number	Article Number	E-Number	Screw Included
ZT605HD	313260	1500671	Yes
ZTA605	388080	1500635	No
ZTA605S6	387190	1500617	No

ADDITIONAL PRODUCT DETAILS

Indicated loads are based on installation with 1/2" (M12) hardware and strut channel type A.

DIAGRAMS

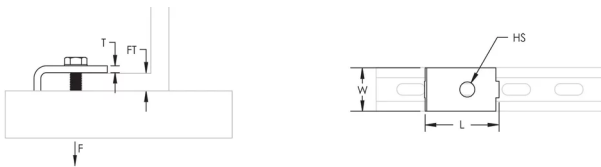

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

