

TDHM Trapezoidal Deck Hanger with Threaded Nut



CERTIFICATIONS



FEATURES

Easy install

Use TDHP perforation tool to punch hole in decking

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/2

Catalog Number	Article Number	E-Number	Rod Size (RS)	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Hole Size 3 (HS3)
TDHM10	179950	1511538	10	6.8 mm	14 mm	10 1/2mm
TDHM8	179940	1511537	8	6.8 mm	14 mm	10 1/2mm


CatalogNumber	Article Number	E-Number	Rod Size (RS)	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Hole Size 3 (HS3)
TDHM6	179930	1511536	6	6.8 mm	14 mm	10 1/2mm

Table 2/2

Catalog Number	Article Number	E-Number	D
TDHM10	179950	1511538	50 mm Max
TDHM8	179940	1511537	50 mm Max
TDHM6	179930	1511536	50 mm Max

Ceiling Thickness	Static Load F
0,63 mm - 0,70 mm	600 N
0,71 mm - 0,80 mm	700 N
0,81 mm - 1,00 mm	800 N
1,01 mm - 1,20 mm	1000 N
1,21 mm - 1,50 mm	1200 N
> 1,50 mm	1500 N

DIAGRAMS

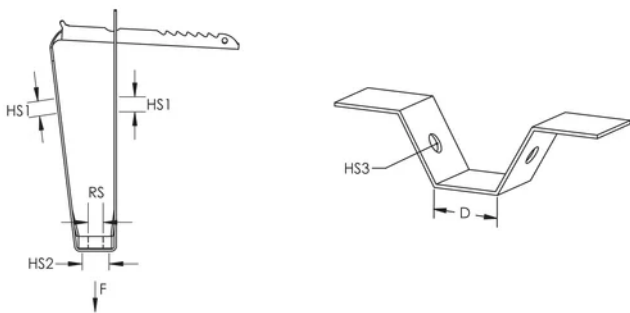

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

