

Ground Rod Clamp with Prefabricated Pigtail



FEATURES

Prefabricated assembly including grounding clamp with pigtail

Fast and simple installation requires only a hammer

SPECIFICATIONS

Material: Copper

Insulation: Green and Yellow Insulated Cable

Table 1/2


Catalog Number	Article Number	E-Number	Ground Rod Diameter, Nominal	Length (L)	Pigtail Length	Conductor Size
EPT1225300	158610	0682689	1/2"	70mm	300mm	25 mm ² Stranded
EPT1425350	158675	0682690	5/8"	75mm	350mm	25 mm ² Stranded
EPT1450350	158290		5/8"	75mm	350mm	50 mm ² Stranded

Table 2/2

Catalog Number	Article Number	E-Number	Unit Weight
EPT1225300	158610	0682689	0.5 kg

Catalog Number	Article Number	E-Number	Unit Weight
EPT1425350	158675	0682690	0.5 kg
EPT1450350	158290		0.5 kg

DIAGRAMS

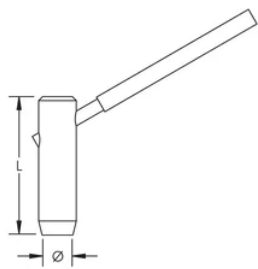

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE