

Ground Rod Clamp, U-Bolt, Bare, One Conductor



FEATURES

Accepts conductors in both parallel and perpendicular orientations

For use with copper-bonded ground rods

SPECIFICATIONS

Material: Leaded Gunmetal;Stainless Steel 316 (EN 1.4401)

Table 1/2


Catalog Number	Article Number	E-Number	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Conductor Size	Complies With
GUV16070	710400		5/8" - 1"	14.2 - 23.2 mm	#4 Solid - 2/0 Stranded, 16 mm ² Stranded - 70 mm ² Stranded	IEC® EN 62561-1
GUV70185	710410	0632369	5/8" - 1"	14.2 - 23.2 mm	#4 Solid - 300 kcmil Stranded, 70 mm ² Stranded - 185 mm ² Stranded	IEC® EN 62561-1

Table 2/2

Catalog Number	Article Number	E-Number	Unit Weight
GUV16070	710400		0.24 kg

Catalog Number	Article Number	E-Number	Unit Weight
GUV70185	710410	0632369	0.25 kg

DIAGRAMS

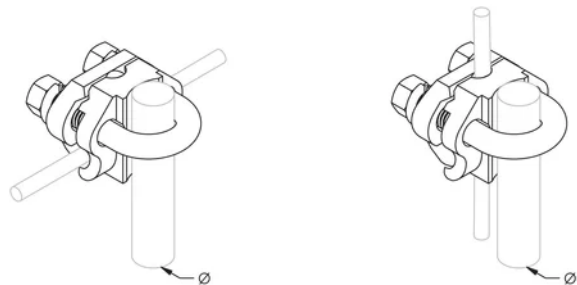

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE