

Multi-Purpose Grounding Clamp



FEATURES

Cross connector for round-to-round, round-to-tape, and tape-to-tape connections

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	Conductor Size	Tape Size
CCFR308	545270	0682623	Brass		8 mm Stranded, 8 mm Solid	25 x 3 mm, 30 x 2 mm
CCG308	545180	0682625	Steel	Hot-Dip Galvanized	8 mm Stranded, 8 mm Solid	25 x 3 mm, 30 x 2 mm
CCS-308	545170	0682624	Stainless Steel 304 (EN 1.4301)		8 mm Stranded, 8 mm Solid	25 x 3 mm, 30 x 2 mm

Table 2/2

Catalog Number	Article Number	E-Number	Depth (D)	Width (W)	Unit Weight
CCFR308	545270	0682623	56mm	56 mm	0.15 kg
CCG308	545180	0682625	56mm	56 mm	0.15 kg
CCS-308	545170	0682624	56mm	56 mm	0.15 kg

DIAGRAMS

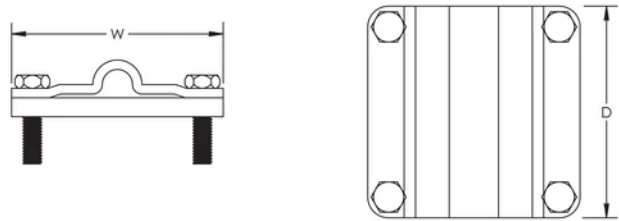

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE